

FTUO



FTUO Fiber Termination Unit Outdoor Wall outlet

This box is typically used as a transition point where the OSP cable is spliced to an indoor cable.

Features and benefits

- Compact enclosure (168 x 132 x 33 mm)
- The box allows the installation of fibers with a minimum bend radius of 25 mm over a length of 2m.
- In-line and butt configuration possible for main cable
- Universal splice holder for 8 splices: SMOUV, ANT splice.
- Ready for CommScope OCC1 splitter installation
- Cable inlet is provided at the bottom left side. Optionally the main cable can continue at the top left side. (wraparound pass-through)
- Cable outlet ports (max. 2 cables) are provided at 5 sides: left, right, top, bottom, back
- IP 43 when cable enters from bottom;
- IP40 when cable enters from top
- Impact rating: IK08
- UV resistant housing
- Standard colour: RAL7035 grey
- Gasventing provided
- Locking with screw, optionally security seal
- Main cable up to 12 mm diameter
- Drop cable up to 5 mm diameter

Product Classification


Regional Availability	EMEA
Product Type	Fiber wall outlet
Product Series	FTUO

General Specifications

Functionality	Splicing
Access	Front
Color	Gray
Lock Type	Locking screw
Mounting	Wall

Ordering Tree

FTUO

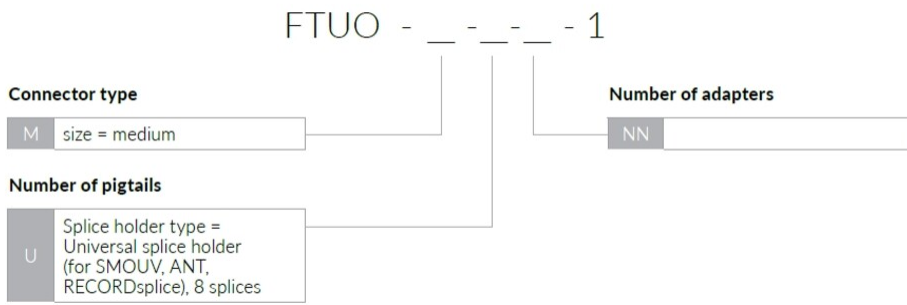

Material Specifications

Enclosure Material Type Polycarbonate + ASA

Environmental Specifications

Environmental Space Outdoor

Flammability Rating UL 94 V-0

UV Resistance UV stabilized

Packaging and Weights

Included Hook and loop fastener | Rubber seal | Silicone tube | Splice protector holder | Tie wraps

Packaging quantity 1

Packaging Type Box | Carton