

Fiber Optic Pigtail, Simplex, Singlemode, SC/UPC to Stub, yellow, 20 m

Product Classification

| | |
|------------------------------|-------------------------|
| Regional Availability | EMEA |
| Product Type | Fiber pigtail, jacketed |
| Product Series | OCP |

General Specifications


| | |
|-------------------------------|--------|
| Connector A, quantity | 1 |
| Color, boot A | Blue |
| Color, connector A | Blue |
| Interface, Connector A | SC/UPC |
| Jacket Color | Yellow |
| Total Fibers, quantity | 1 |

Dimensions

| | |
|--------------------|------------------|
| Cord Length | 20 m 65.617 ft |
|--------------------|------------------|

Ordering Tree

2-2160565-0 | OCP-SF-20MASIA-XX

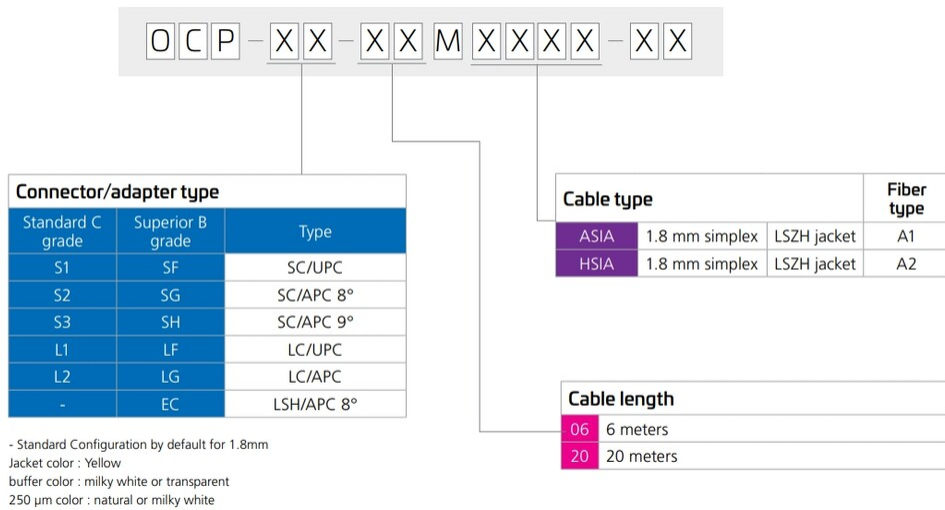

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A1, TeraSPEED®

Environmental Specifications

Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |

