


760060343 | VP360-HCM-Kit-19

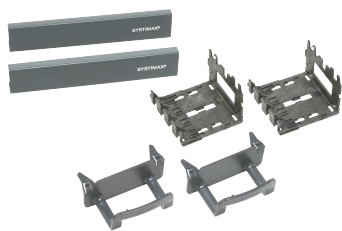

GigaSPEED X10D® VisiPatch® 360 Horizontal Cable Management Kit, 19 In.

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Cable management hardware
Product Brand	VisiPatch®

General Specifications

Product Design	VisiPatch® 360
ANSI/TIA Category	6A

Dimensions

Width	482.6 mm 19 in
Depth	299.72 mm 11.8 in

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Safety Standard	Austel CE UL cUL

Packaging and Weights

Included	Two horizontal CM troughs Two horizontal trough covers Two pairs of back panel halves
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

UK-ROHS

Compliant

