


# XA-U

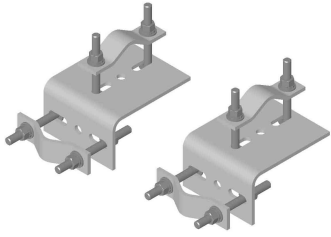

Universal Crossover Angle, 2 in to 3-1/2 in

## Product Classification

**Product Type** Mounting kit

## General Specifications

**Mounting** Pipe, 50.8–88.9 mm (2–3 1/2 in) OD

**Tower Taper** Non-tapered | Tapered

## Dimensions

**Height** 101.6 mm | 4 in

**Length** 101.6 mm | 4 in

**Mounting Diameter, maximum** 88.9 mm | 3.5 in

**Mounting Diameter, minimum** 50.8 mm | 2 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Angle | Clamps

**Packaging quantity** 2

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant

