

1-1920743-7



Fiber Optic Patch Cord, LC to LC, duplex, OM3 XG 10 Gb/s, twin zip, 17 m, aqua

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	192

General Specifications


Connector A, quantity	2
Color, boot A	Beige
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Beige
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Total Fibers, quantity	2

Dimensions

Cord Length	17 m 55.774 ft
Diameter Over Jacket	1.8 mm 0.071 in

Ordering Tree

1-1920743-7

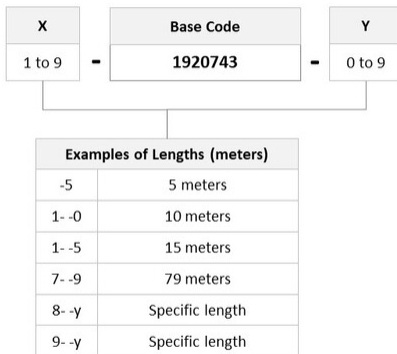

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM3, LazrSPEED®
Insertion Loss, maximum, connector A	0.15 dB
Insertion Loss, maximum, connector B	0.15 dB
Return Loss, minimum, connector A	35 dB
Return Loss, minimum, connector B	35 dB

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

1-1920743-7

