

FPX-24MPRQA6

FPX Fiber Optic MPO Module, Multimode OM4, 24 fiber LC adapter, right, putty white

- FPX modules offer the end-user the flexibility of a plug-and-play MPO architecture with a “grow as you go” approach to the network
- Each module has a front bulkhead identical to the adapter pack with an internal cable assembly converting to an MPO male connector
- All fiber connectivity is housed in an enclosed module with a rear MPO adapter allowing the user to utilize an MPO trunk to turn up service

Product Classification

| | |
|------------------------------|---------------|
| Regional Availability | North America |
| Portfolio | CommScope® |
| Product Type | Fiber module |
| Product Series | FPX |

General Specifications


| | |
|-------------------------------------|----------------------------|
| Functionality | Breakout |
| Application | For use with FPX panels |
| Adapter Color | Aqua |
| Adapters, quantity, front | 12 |
| Adapters, quantity, rear | 2 |
| Body Style | Duplex Right orientation |
| Color, front | Putty white |
| Color, housing | Putty white |
| Color, rear | Putty white |
| Interface, front | LC/UPC |
| Interface, rear | MPO |
| Interface Feature, rear | Standard |
| Polarity | Pairs, straight |
| Total Ports, quantity, front | 24 |

Dimensions

| | |
|---------------|---------------------|
| Height | 33.02 mm 1.3 in |
| Width | 176.53 mm 6.95 in |
| Depth | 127 mm 5 in |

FPX-24MPRQA6

Ordering Tree

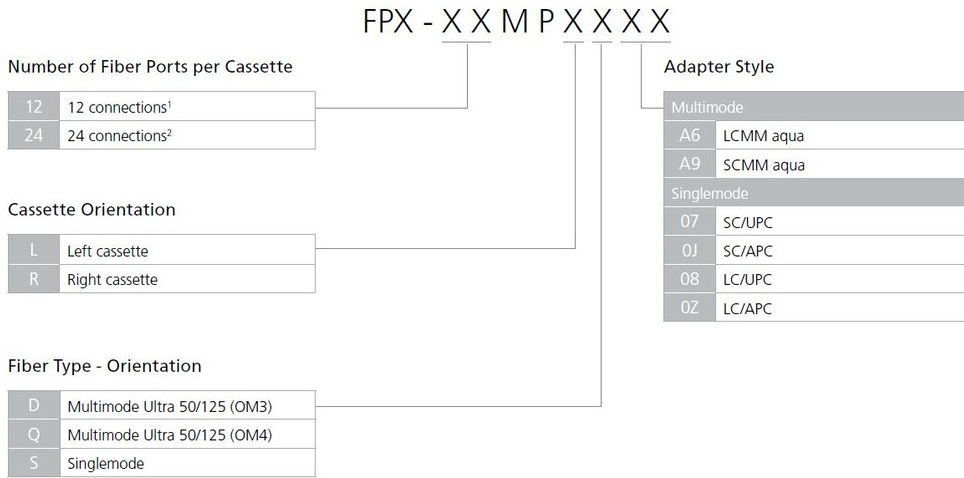

¹ SC only

² LC only

Optical Specifications

| | |
|-------------------|-----------|
| Fiber Mode | Multimode |
| Fiber Type | OM4 |

Environmental Specifications

| | |
|------------------------------|--------------------------------------|
| Operating Temperature | -40 °C to +85 °C (-40 °F to +185 °F) |
| Storage Temperature | -40 °C to +85 °C (-40 °F to +185 °F) |

Packaging and Weights

| | |
|---------------------------|--------------|
| Packaging quantity | 1 |
| Packaging Type | Bag Carton |

Regulatory Compliance/Certifications

| Agency | Classification |
|-------------------|--|
| CHINA-ROHS | Above maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |
| TL 9000:2016 (R6) | Compliant to this quality management practice |

FPX-24MPRQA6

UK-ROHS

Compliant

