


ALXMXLCAD

Base Product

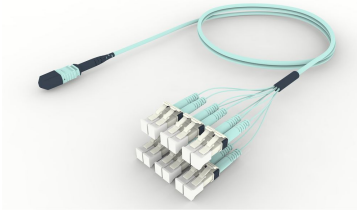

OM4 MPO12 (Pinned) to LC/UPC, Ruggedized Fanout Fiber Cable, 12-Fiber, Plenum

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Aqua
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Male
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Polarity	Method A
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	7 – 999

ALXMXLCAD

Ordering Tree

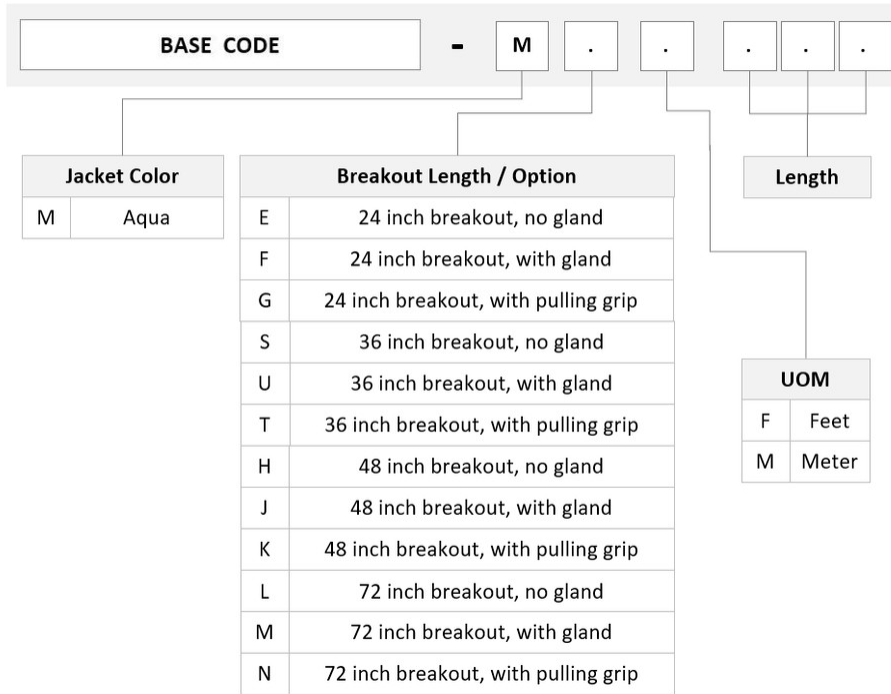

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value

ALXMXLCAD

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760155945 P-012-MP-8W-F12AQ	-	Fiber indoor cable, TeraSPEED® Plenum for MPO Trunks, 12 fiber, Singlemode G.652.D and G.657.A1, Feet jacket marking, Aqua jacket color
860366228	-	MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm
860637378	-	LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode