


Fiber Optic Pigtail, Simplex, Singlemode, LC/UPC to Stub, 2 m

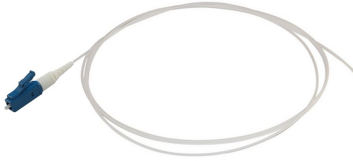

Product Classification

Regional Availability	Europe Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed

General Specifications

Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Interface, Connector A	LC/UPC
Jacket Color	White
Total Fibers, quantity	1

Dimensions

Cord Length	2 m 6.562 ft
Diameter Over Jacket	0.9 mm 0.035 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum, connector A	0.3 dB
Return Loss, minimum, connector A	45 dB

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

