


# 760005348 | M81-RCA-110-246-Y

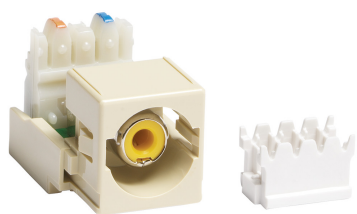

M81 RCA to 110 Punchdown Module Audio and Video Adapter, ivory housing yellow connector

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Multimedia outlet

## General Specifications

<b>Color</b>	Ivory
<b>Color, RCA</b>	Yellow
<b>Mounting</b>	Snap-in
<b>UTP 110 Terminal Block</b>	110 ohm

## Electrical Specifications

<b>Attenuation dc at Frequency, maximum</b>	2 dB @ 5.5 MHz
<b>Crosstalk @ Gain at Frequency</b>	-60 dB @ 5.5 MHz
<b>Impedance</b>	75 ohm
<b>Insulation Resistance, minimum</b>	50 MOhm

## Material Specifications

<b>Material Type</b>	High-impact, flame retardant, thermoplastic
----------------------	---

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Storage Temperature</b>	-40 °C to +70 °C (-40 °F to +158 °F)
<b>Relative Humidity</b>	5%–95%, non-condensing
<b>Flammability Rating</b>	UL 94 V-0

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

**Agency**

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system