

# FSB-SBJ23200C00000

---



FSB Fiber Splitter Box, indoor, SC/APC, 32 ports, putty white, splice tray for heat shrink fusion, with adapters and 900 $\mu$  pigtails

## Product Classification

<b>Regional Availability</b>	North America
<b>Product Type</b>	Fiber splitter box
<b>Product Series</b>	FSB

## General Specifications


<b>Functionality</b>	Patching   Splitting
<b>Adapters, quantity</b>	32
<b>Color</b>	Putty white
<b>Front Door Type</b>	Double hinged
<b>Interface</b>	SC/APC
<b>Lock Type</b>	Key lock
<b>Mounting</b>	Wall
<b>Port, quantity</b>	32

## Dimensions

<b>Height</b>	203 mm   7.992 in
<b>Width</b>	330 mm   12.992 in
<b>Depth</b>	127 mm   5 in

## Ordering Tree

# FSB-SBJ23200C00000

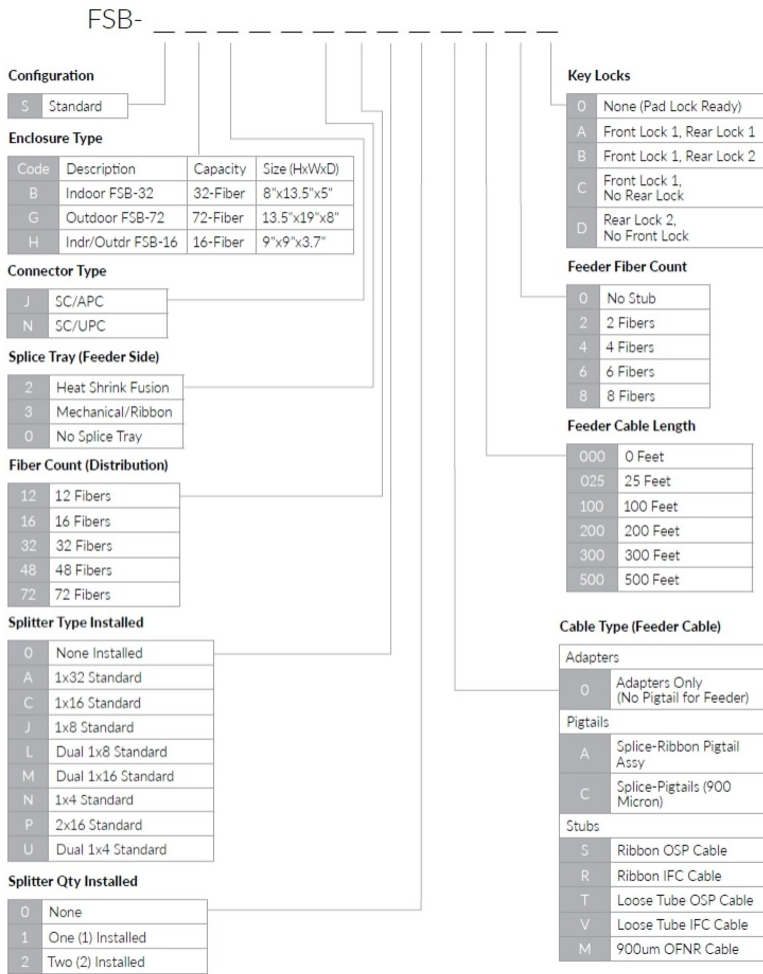

## Material Specifications

**Finish** Powder coated

**Material Type** Steel

## Optical Specifications

**Fiber Mode** Singlemode

## Environmental Specifications

**Environmental Space** Indoor

## Packaging and Weights

**Packaging quantity** 1

# FSB-SBJ23200C00000

---

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

