

AQXQPQPF8

Base Product



Ultra Low Loss (ULL) OM4 MPO8 (Non-Pinned) to MPO8 (Non-Pinned), Fiber Array Cable Assembly, 8-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Gray
Color, connector A	Aqua
Connector B, quantity	1
Color, boot B	Gray
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Female
Interface, Connector B	MPO-08/UPC Female
Jacket Color	Aqua
Polarity	Method A
Fibers per Subunit, quantity	8
Total Fibers, quantity	8

Dimensions


Cable Assembly Length Range (m)	1 – 305
--	---------

AQXQPQPF8

Cable Assembly Length Range (ft)

3 – 999

Ordering Tree

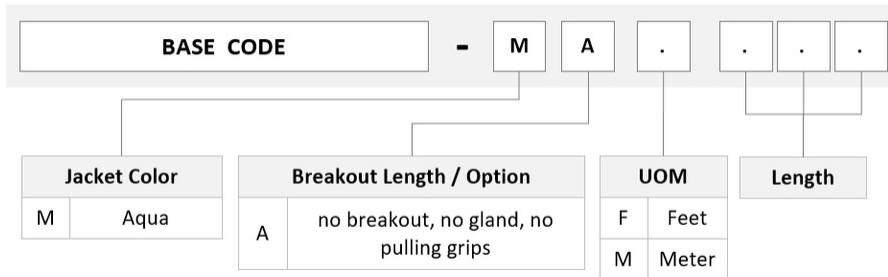

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode

Multimode

Fiber Type

OM4, LazrSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space

Indoor | Plenum

Included Products

- 760248403 P-008-MP-5K-F20AQ – Fiber indoor cable, LazrSPEED® Plenum MPO Light Duty for Patchcords, 8 fiber, Multimode OM4, Feet jacket marking, Aqua jacket color
- 860659024 – MPO-08, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 2mm