


760245727 | CHD12-DM-12LA-SM-AS-LL

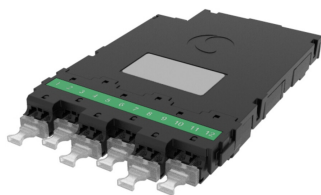

CHD ULL Singlemode MPO-12 distribution module, 12LC/APC to 1x12f MPO pinned, dust plugs

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Series	CHD

General Specifications

Functionality	Breakout
Color, front	Green
Color, rear	Black
Interface, front	LC/APC
Interface, rear	MPO
Interface Feature, rear	Key up/down Pinned
Polarity	Method A Pairs, straight
Shuttered	No

Dimensions

Height	12.45 mm 0.49 in
Width	83.82 mm 3.3 in
Depth	131.83 mm 5.19 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum	0.75 dB

Environmental Specifications

760245727 | CHD12-DM-12LA-SM-AS-LL

Qualification Standards IEC 61753-1 | TIA-568.3-D

Safety Standard CE | CSA | UL

Packaging and Weights

Packaging quantity 1

Weight, net 0.082 kg | 0.18 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

