

FKXMPMPDF

Base Product



OM4 MPO (Unpinned) to MPO (Unpinned), InstaPATCH® 360 Array Cord, 24-Fiber, Low Smoke Zero Halogen

Product Classification

Regional Availability	Asia Australia/New Zealand China India Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications

Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Armored Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Female
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Black
Polarity	Method B (LL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	24


Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999

FKXMPMPDF

Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

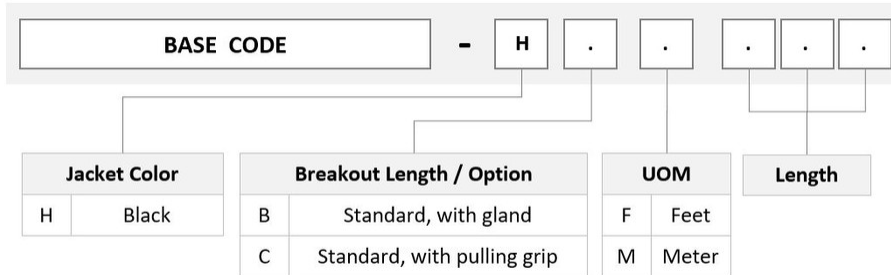

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor/Outdoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760160085 – Fiber indoor/outdoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk,

FKXMPMPDF

Z-024-MZ-5K-F12BK

interlocking aluminum armored, Multimode OM4, 24 fiber multi-unit with 12 fiber subunits, Gel-free, Feet jacket marking, Black jacket color

860647054

-

MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm