


FGS-MDSP-M2B

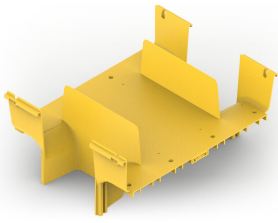

FiberGuide® Downspout, 4x18in, Dual Exit, yellow

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Downspout
Product Brand	FiberGuide®
Product Series	FGS

General Specifications

Color	Yellow
Orientation	Horizontal
Section Type	Downspout

Dimensions

Height	210 mm 8.268 in
Width	498 mm 19.606 in
Length	380 mm 14.961 in
System Dimensions	102 mm x 457 mm (4 in x 18 in)

Ordering Tree

FGS-MDSP-M2B



Section Color

9	empty	yellow
	B	black

Section Size

10	2B	4 x 6 in, 4 x 4 in dual drop
	A	4 x 4 in
	A/I	4 x 4 in, insertable
	B	4 x 6 in, 4 x 4 in drop
	B/I	4 x 6 in, insertable
	C	2 x 2 in, extended
	EX-	extended
	F	4 x 12 in, 4 x 6 in drop
	F/I	4 x 12 in, 4 x 6 in drop, insertable
	G	2 x 6 in, 2 x 2 in drop
	IMP	4 x 6 in, dual drop with divider
	M	4 x 18 in

Material Specifications

Material Type Engineering Thermoplastic

Environmental Specifications

Flammability Rating CSA S143 | UL 2024 | UL 94 V-0

Halogen Characteristics Blue Angel | TCO '99 | WEEE

Safety Standard CSA | UL

Packaging and Weights

Weight, net 1.711 kg | 3.772 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant



