


# 252139

---

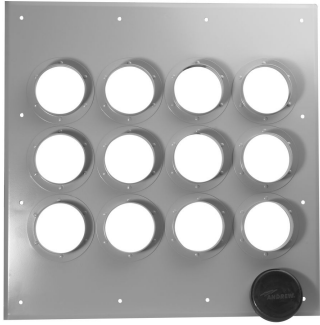

Twelve 4" Port Entrance Panel, 3 x 4

## Product Classification

<b>Product Type</b>	Entrance panel
<b>Product Brand</b>	I-Line
<b>Ordering Note</b>	CommScope® non-standard product

## General Specifications

<b>Color</b>	Gray
<b>Entry Panel Port Size</b>	101.6 mm   4 in
<b>Number of Ports</b>	12
<b>Panel Type</b>	Multiple

## Dimensions

<b>Height</b>	647.7 mm   25.5 in
<b>Width</b>	647.7 mm   25.5 in

## Material Specifications

<b>Material Type</b>	Aluminum
----------------------	----------

## Environmental Specifications

<b>Weather Resistance Test Method</b>	04AS00-03.9.0   IEC 60529:2001, IP66
---------------------------------------	--------------------------------------

## Packaging and Weights

<b>Height, packed</b>	698.5 mm   27.5 in
<b>Width, packed</b>	698.5 mm   27.5 in
<b>Length, packed</b>	1,778 mm   70 in

# 252139

---

<b>Included</b>	Entry cap   Hardware   Port
<b>Packaging quantity</b>	1
<b>Weight, gross</b>	3.62 kg   7.981 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

