


PG-RM06

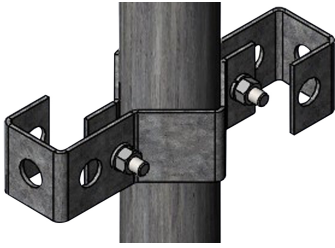

PIM-Guard Round Member Cable Support Bracket 6 ports for stackable hangers (up to 3 per port). Install with torque wrench set at 5 to 7 ft-lb to meet carrier PIM requirements. For patents, see www.cs-pat.com

Product Classification

| | |
|----------------------|-----------------|
| Product Type | Support bracket |
| Product Brand | PIM-Guard |

General Specifications

| | |
|-----------------------------|--|
| Cable Runs, quantity | 6 |
| Hole, quantity | 6 |
| Mounting | Pipe, 60.3–88.9 mm (2-3/8 in to 3-1/2 in) OD |

Dimensions

| | |
|-----------------------------------|--------------------|
| Height | 50.8 mm 2 in |
| Width | 50.8 mm 2 in |
| Length | 198.12 mm 7.8 in |
| Mounting Diameter, maximum | 60.96 mm 2.4 in |
| Mounting Diameter, minimum | 88.9 mm 3.5 in |
| Hole Size | 3/4 in |

Material Specifications

| | |
|----------------------|--------------------------|
| Material Type | Hot dip galvanized steel |
|----------------------|--------------------------|

Packaging and Weights

| | |
|---------------------------|-------------------|
| Packaging quantity | 1 |
| Weight, net | 2.3 kg 5.071 lb |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

PG-RM06

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

