



Mini-OPE 200-Series, Optical Terminal Enclosure, 8-port full-size connector, 1x8 PLC splitter, black, pole mount

- Optical Terminal Enclosures incorporate hardened connector technology that is designed to withstand the rugged outside plant environment
- Functionality to splice and store feeder cable in the field with the possibility to splice in the field two extra branch cables
- Hardened adapters are factory-terminated and environmentally sealed to ensure rapid plug-and-play drop cable installations
- Integrated external cable fixation guarantees easy, fast and reliable cable manipulations

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America
<b>Product Type</b>	Access terminal, with splitter
<b>Product Series</b>	Mini-OPE 200


## General Specifications

<b>Cable Sealing Type</b>	Compressed gel
<b>Cable Type</b>	No cable (stubless)
<b>Distribution Type</b>	1 x 8 splitter
<b>Drop Port Type</b>	Hardened full-size SC/APC
<b>Drop Port, quantity</b>	8
<b>Enclosure Color</b>	Black
<b>Mounting</b>	Handhole   Pole   Wall
<b>Split Ratio</b>	Symmetrical
<b>Splitter, quantity</b>	1
<b>Stub Type</b>	No stub


## Dimensions

<b>Height</b>	358.5 mm   14.114 in
<b>Width</b>	166 mm   6.535 in
<b>Depth</b>	129.3 mm   5.091 in
<b>Cable Length, stub</b>	0 ft (0 m)

## Dimension Drawing

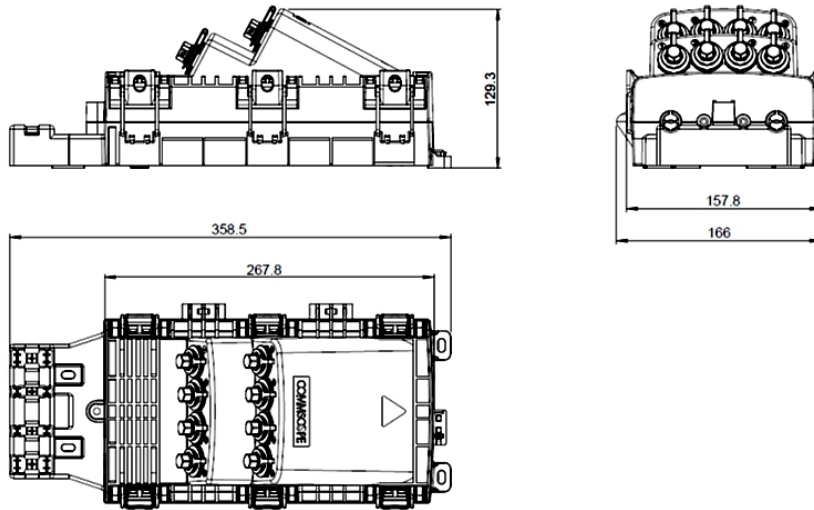

## Ordering Tree

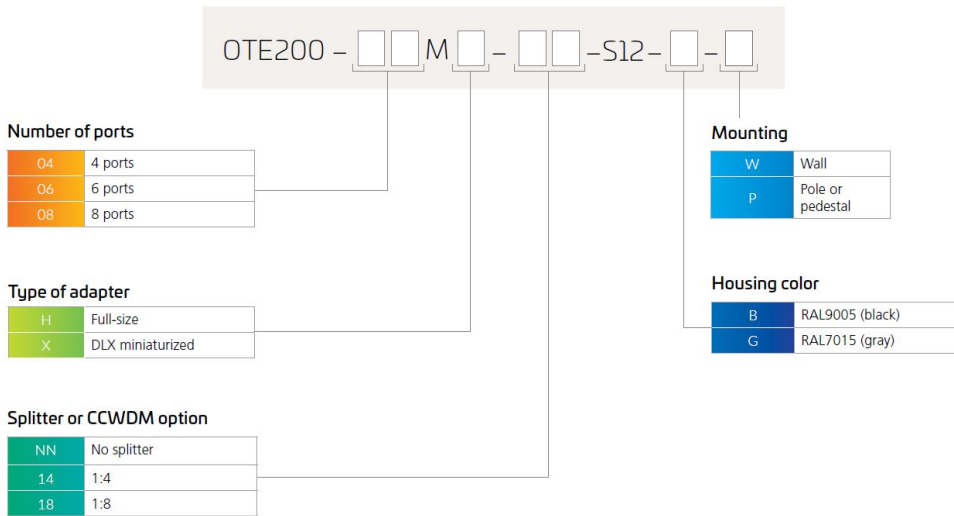

## Material Specifications

**Enclosure Material Type** Glass filled polypropylene (GF-PP)

## Optical Specifications

**Fiber Type** G.657.A2

**Operating Wavelength Range** 1260 – 1635 nm

**Attenuation Single Ports, typical** 10.8 dB

# 760252937 | OTE200-08MH-18-S12-B-P

---

**Return Loss, Single Ports, minimum** 55 dB

## Environmental Specifications

**Operating Temperature** -40 °C to +65 °C (-40 °F to +149 °F)  
**Relative Humidity** 5%–100%, condensing  
**Environmental Space** Above ground | Below ground | Buried  
**Qualification Standards** IEC 60529, IP68 + 2 m waterhead  
**UV Resistance** UV stabilized

## Packaging and Weights

**Included** Cable termination unit (2) | Enclosure (1) | Fiber pigtail cassette (1) | Splice Cassette (2)  
**Packaging quantity** 1  
**Packaging Type** Box | Carton  
**Weight, net** 1.77 kg | 3.902 lb

## Included Products

CW8094-002 – TENIO™ Cable Termination Unit kit  
TENIO-CTU-L-(10)