


FD3-AC144J00PBPP2-US

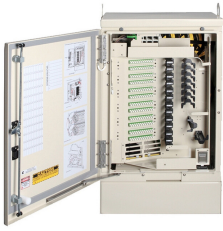

FDH 3000 Fiber Distribution Extra Small Cabinet, 144F, SC/APC, no splitters, dielectric loose tube, 100 ft, 24F, Build America Buy America (BABA)

- *CommScope intends to release this product at a future date. At such time, this product will comply with the requirements of the Build America, Buy America Act and/or applicable waivers. Compliance requirements and waiver applicability vary based on government funding program. Check the laws and regulations for your specific program.

Product Classification

| | |
|------------------------------|---|
| Regional Availability | North America |
| Product Type | Fiber distribution hub |
| Product Series | FDH 3000 |
| Government Funding | Build America Buy America (BABA) coming soon* |

General Specifications

| | |
|--|-------------------------|
| Access | Front |
| Cable Type | Dielectric - Loose Tube |
| Color | Putty white |
| Distribution Cables, quantity | 1 |
| Distribution Ports, quantity | 144 |
| Fibers per Distribution Cable, quantity | 144 |
| Fibers per Feeder Cable, quantity | 24 |
| Interface, Input | SC |
| Interface Feature, Input | APC |
| Mounting | Pad |
| Splitter Slots, quantity | 9 |

Dimensions

| | |
|---------------------|------------------|
| Height | 914.4 mm 36 in |
| Width | 533.4 mm 21 in |
| Depth | 355.6 mm 14 in |
| Cable Length | 30.48 m 100 ft |

FD3-AC144J00PBPP2-US

Enclosure Size Extra small

Material Specifications

Finish Powder coated

Material Type Steel

Environmental Specifications

Environmental Space Above ground

Packaging and Weights

Packaging quantity 1

Packaging Type Pallet

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|-----------------------------------|
| CHINA-ROHS | Above maximum concentration value |
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

