

# MPJ2DBBGNN10M

---



HELIAX® Modular Remote Radio Head Power Cable Assembly, 2 conductors Black/Blue 10mm<sup>2</sup>, Blunt Cut to OEC GEN; CPR rated Cca s1, d1, a1. 10 meter

## Product Classification

<b>Regional Availability</b>	Asia   EMEA   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Power cable assembly
<b>Product Brand</b>	HELIAX®
<b>Product Series</b>	Modular
<b>Ordering Note</b>	CommScope® standard product (Global)

## General Specifications


<b>Cable Type</b>	Power
<b>Conductors, quantity</b>	2
<b>Construction Type</b>	Non-armored
<b>Jacket Color</b>	Black

## Dimensions

<b>Cord Length</b>	10 m   32.808 ft
<b>Diameter Over Dielectric</b>	4.724 mm   0.186 in
<b>Diameter Over Jacket, nominal</b>	16.789 mm   0.661 in
<b>Center Conductor Gauge</b>	10 mm <sup>2</sup>

## Ordering Tree

# MPJ2DBBGNN10M

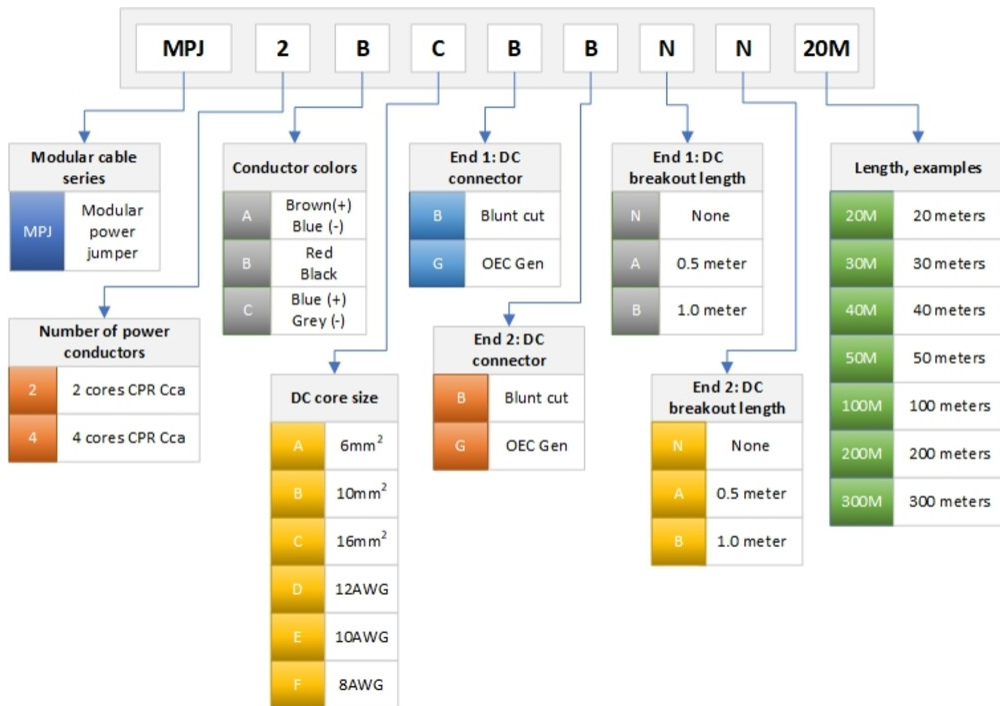

## Material Specifications

<b>Dielectric Material</b>	PVC
<b>Filler Material</b>	Polypropylene
<b>Jacket Material</b>	PE

## Mechanical Specifications

<b>Minimum Bend Radius</b>	156 mm   6.142 in
<b>Cable Retention Strength, maximum</b>	90 N (OEC GEN)

## Environmental Specifications

<b>Operating Temperature</b>	-40 °C to +75 °C (-40 °F to +167 °F)
<b>Environmental Space</b>	UV resistant for outdoor and/or direct burial installations
<b>Flame Test Method</b>	CMP
<b>Flammability Rating</b>	CMP