


M81-HDMI-PT-266 Pass-Through Connector, Pro white

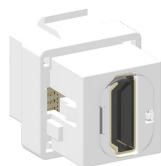

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Multimedia outlet

General Specifications

Application	Module designed for audio/video applications
Color	Pro white
Mounting	Snap-in

Dimensions

Height	23.876 mm 0.94 in
Width	21.336 mm 0.84 in
Depth	31.496 mm 1.24 in

Electrical Specifications

Insulation Resistance, minimum	100 MOhm
---------------------------------------	----------

Material Specifications

Material Type	High-impact, flame retardant, thermoplastic
----------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	5%–95%, non-condensing

760190686 | M81-HDMI-HDMI-266

Flammability Rating UL 94 V-0
Safety Standard CSA | HDMI 1.4 | UL

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

