


E20® Coaxial/Microduct Hybrid Buried Cable

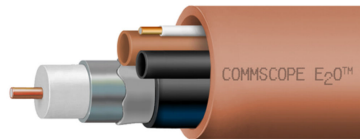

- E20 is a solution that enables service providers the ability to bridge HFC networks to FTTx. The E20 composite coaxial/fiber product line combines fiber, microducts, and coaxial cable preinstalled in conduit.
- Serves businesses in a new commercial serving area
- Mitigates future cost of fiber installation
- Pre-installed in high density PE conduit for added physical protection
- One-step installation saves on construction cost
- Ideal for commercial data customers that also require video
- All products tested to industry standards

Product Classification

Product Type	Coaxial fiber cable-in-conduit
Product Brand	E20®

General Specifications

Cable Series	P3 875
--------------	--------

Dimensions

Height	60.325 mm 2.375 in
Width	60.325 mm 2.375 in
Outer Jacket Thickness, nominal	4.724 mm 0.186 in

Material Specifications

Outer Jacket Material	High density polyethylene (HDPE)
-----------------------	----------------------------------

Mechanical Specifications

Minimum Bend Radius	660.4 mm 26 in
Pulling Tension, maximum	1,170.268 kg 2580 lb

Environmental Specifications

Environmental Space	Buried
---------------------	--------

Packaging and Weights

Weight, gross	1,285.774 kg/km 864 lb/kft
---------------	------------------------------

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



Included Products

359998100 16MT DUCT EMPTY	-	ConQuest® Empty Conduit, 16 mm, SDR 11, terracotta
359998400 16MT DUCT EMPTY	-	ConQuest® Empty Conduit, 16 mm, SDR 11, terracotta
360000000 12.7MB DUCT EMPTY	-	ConQuest® Empty Conduit, 12.7 mm, black
360000013 12.7MB DUCT EMPTY	-	ConQuest® Empty Conduit, 12.7 mm, black
5309103 P3® 875 JCASS	-	75 Ohm P3® Trunk and Distribution Cable, black PE jacket, flooded for underground
5309193 P3® 875 JCASS	-	75 Ohm P3® Trunk and Distribution Cable, black PE jacket, flooded for underground
8220001 PP Coated Tone Wire 0.0403 CCS	-	E20® Coaxial/Microduct Hybrid Buried Cable
CX3799839 200T135 EMPTY DUCT COEX	-	ConQuest® Empty Conduit, 2 in, SDR 13.5, terracotta