


# MC-SA24-B

---

Stand-off Arm -24 in with U-bolts for 2-3/8" Pipe

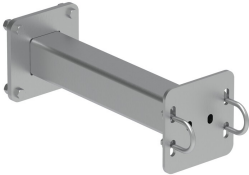

## Product Classification

**Product Type** Support arms for ring mount

## General Specifications

**Mounting** Ring mount

**Pipe, quantity** 0

## Dimensions

**Height** 254 mm | 10 in

**Width** 254 mm | 10 in


**Length** 609.6 mm | 24 in

**Stand-off Distance** 609.6 mm | 24 in

## Outline Drawing

# MC-SA24-B

---

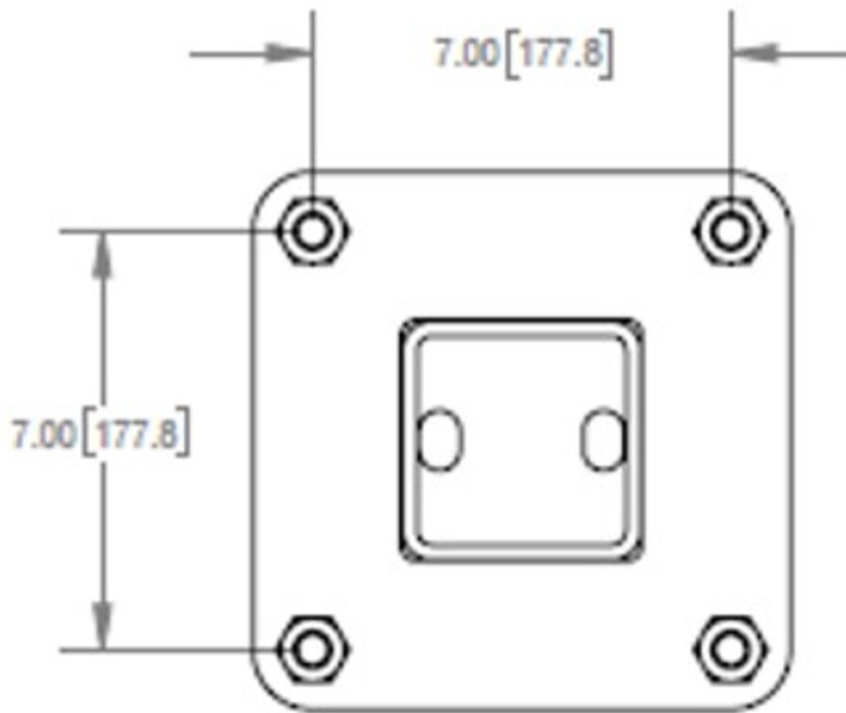

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating** For Specifications, please contact [steelproducts@commscope.com](mailto:steelproducts@commscope.com) or call 800-255-1479

**Wind Rating Test Method** TIA/EIA-222-G

## Packaging and Weights

**Included** Hardware | Stand-off arms | U-bolts

**Packaging quantity** 1

**Weight, net** 26.8 kg | 59.084 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value

# MC-SA24-B

---

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant



## \* Footnotes

**Wind Rating**                      BWS—Base Wind Speed; FBC—Florida Building Code