

Monopole Co-Location Platforms for 12” to 50” Monopoles: New Product *Global Communication*

CommScope is now offering three new Monopole Co-Location Platform product families designed for monopoles ranging from 12” to 50” OD:

- MC-PK-M Series Low Profile Co-Location Platform
- MC-CP-M Series Medium Capacity Co-Location Platform
- MC-HP-M Series High Capacity Co-Location Platform

All three product families are available as a base kit with ring mount and platform only or as a complete kit that includes the antenna pipes, handrails and mounting hardware. The monopole mounts are also available with the option of a 12’ 6” face or 14’ 6” face.

Features:


- Fits 12” to 50” Monopoles
- 3 Sector Solutions
- 12.5’ and 14.5’ Face Options
- Available as Base Kit or Full Kit with Pipes
- Hot Dip Galvanized Steel
- AISC Certified Manufacturing

Support Information:


Please contact steelproducts@commscope.com for any additional information. **Office:** 817-864-4112.



MC-PK-M Series Low Profile Platform

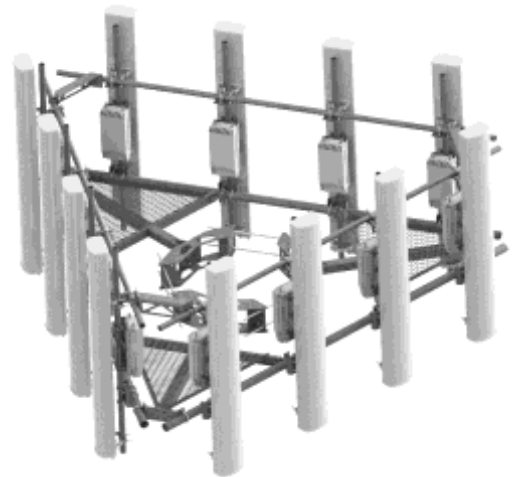

MC-CP-M Series Medium Capacity Platform

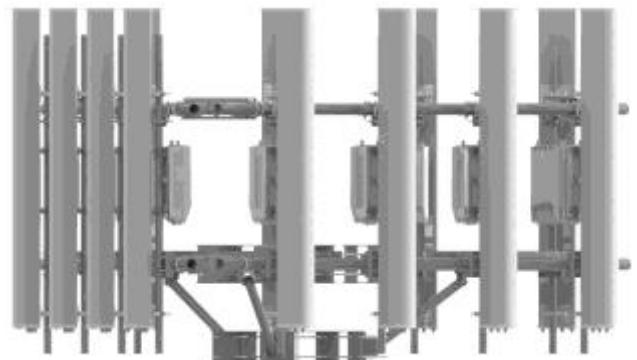

MC-HP-M Series High Capacity Platform

Ordering Information:

MC-PK-M Series – Low Profile Co-Location Platforms

Part Number	Description – Fits Monopoles 12” to 50” OD
MC-PK12M-B	Low-Profile Co-location Platform Base Kit, 12.5 ft face
MC-PK12M-12-96	Low-Profile Co-location Platform Kit, 12.5 ft face, includes twelve 96” pipes
MC-PK12M-12-126	Low-Profile Co-location Platform Kit, 12.5 ft face, includes twelve 126” pipes
MC-PK14M-B	Low-Profile Co-location Platform Base Kit, 14.5 ft face
MC-PK14M-12-96	Low-Profile Co-location Platform Kit, 14.5 ft face, includes twelve 96” pipes
MC-PK14M-12-126	Low-Profile Co-location Platform Kit, 14.5 ft face, includes twelve 126” pipes

MC-CP-M Series – Medium Capacity Co-Location Platforms

Part Number	Description – Fits Monopoles 12” to 50” OD
MC-CP12M-B	Medium Capacity Co-location Platform Base Kit, 12.5 ft face
MC-CP12M-12-96	Medium Capacity Co-location Platform Kit, 12.5 ft face, includes twelve 96” pipes
MC-CP12M-12-126	Medium Capacity Co-location Platform Kit, 12.5 ft face, includes twelve 126” pipes
MC-CP14M-B	Medium Capacity Co-location Platform Base Kit, 14.5 ft face
MC-CP14M-12-96	Medium Capacity Co-location Platform Kit, 14.5 ft face, includes twelve 96” pipes
MC-CP14M-12-126	Medium Capacity Co-location Platform Kit, 14.5 ft face, includes twelve 126” pipes

MC-HP-M Series – High Capacity Co-Location Platforms

Part Number	Description – Fits Monopoles 12” to 50” OD
MC-HP12M-B	High Capacity Co-location Platform Base Kit, 12.5 ft face
MC-HP12M-12-96	High Capacity Co-location Platform Kit, 12.5 ft face, includes twelve 96” pipes
MC-HP12M-12-126	High Capacity Co-location Platform Kit, 12.5 ft face, includes twelve 126” pipes
MC-HP14M-B	High Capacity Co-location Platform Base Kit, 14.5 ft face
MC-HP14M-12-96	High Capacity Co-location Platform Kit, 14.5 ft face, includes twelve 96” pipes
MC-HP14M-12-126	High Capacity Co-location Platform Kit, 14.5 ft face, includes twelve 126” pipes