

RealFlex® Pushable Hardened Drop Cable: New Product

CommScope's new Pushable Hardened Drop cable is the latest development in our expanding drop cable portfolio. The Pushable drop is a dielectric Indoor/Outdoor drop cable, factory terminated with a Full Size SC/APC or DLX hardened connector to a stub end.



Features and Benefits


- Cable is flexible yet stiff, enabling it to be pushed by hand into duct sizes ranging from 1/8" (6mm) to 3/8" (10mm) ID
- Available in LSZH or MDPE outer jackets
- All drop cable lengths will be supplied on spools
- Plug-and-Play solution for durable and reliable service connections
- Technician friendly to simplify installation and maintenance by minimizing splicing



Pushable Distance Feet (m)				
Jacket	3/8" (10 mm) ID Duct**		1/8" (6 mm) ID Duct**	
	w/o Air	With Air	w/o Air	With Air
LSZH	500 (150)	1970 (600)	500 (150)	860 (260)
MDPE	300 (90)	1970 (600)	400 (120)	600 (180)

*Results are based on an independent field trial and may vary per installation.

Ordering Tree

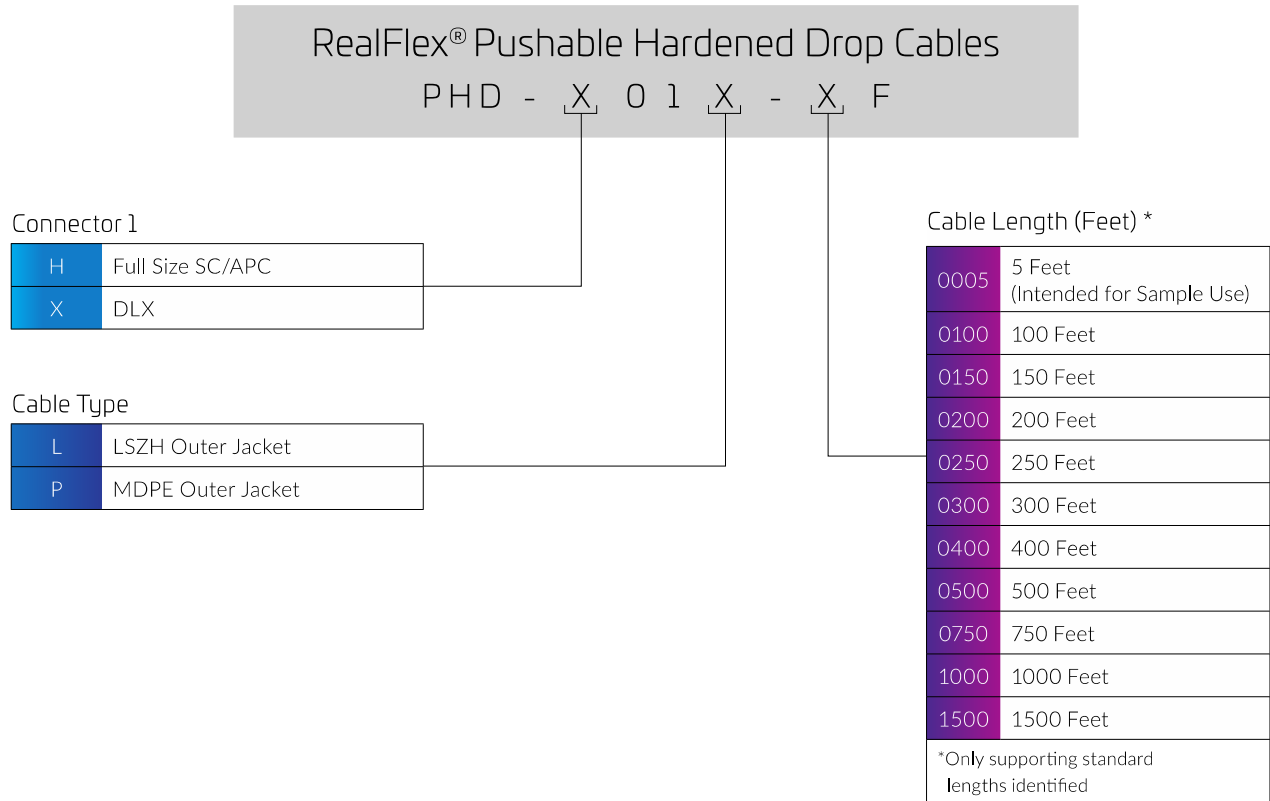

- Note that the pushable blunt end is not intended to be used with gel-based sealing.

Additional Information

- See [ECAT](#) for complete product information

Support Information

Please visit our Fiber drop cable solutions brochure for additional information regarding the portfolio.

<https://www.commscope.com/solutions/hardened-fiber-connector-system/>

Please contact customer service for pricing and availability.