



Outside Plant Rollable Ribbon Fiber Cables: New Product

CommScope is pleased to announce our new rollable ribbon fiber cables. Rollable ribbon is one of the industry's most innovative technologies specially designed to solve today's challenging needs for increased density and reduced footprint in applications ranging from data centers, to FTTx distribution hubs, access network closures, and terminals.

With up to 3456 fibers in a single cable, which can be routed in a 2-inch pathway, the new rollable ribbon cable portfolio offers exceptional carrying capacity for high-growth, high-bandwidth applications with reduced duct system cost and space. In addition, a completely gel-free design helps reduce the time required to prepare for splicing, therefore reducing labor costs.



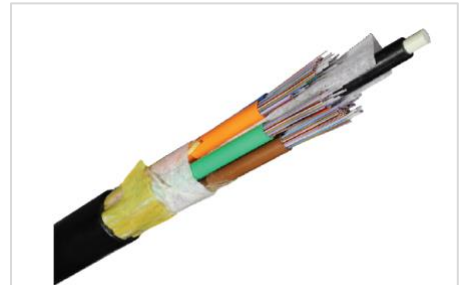


Rollable Ribbon Fiber Cable
Standard Loose Tube Series

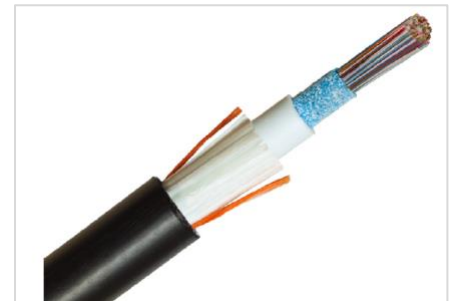

Rollable Ribbon Fiber Cable
Central Tube Series

- ITU-T G.652.D/G.657.A1 single mode glass
- 250µm glass
- Ultra-high fiber density with reduced footprint and weight
- 2X fiber density (more fiber and less space) versus flat ribbon designs
- Central tube designs available in 144 & 288 fiber counts
- Stranded loose tube designs available in 432, 576, 864, 1728, and 3456 fiber counts
- Reduced splicing prep time by up to 80% (over traditional gel-filled ribbon cable designs)
- Completely gel-free design
- Optimized for fast, cost effective mass splicing
- Meets GR-20 Issue 4 and ANSI/ICEA S-87-640

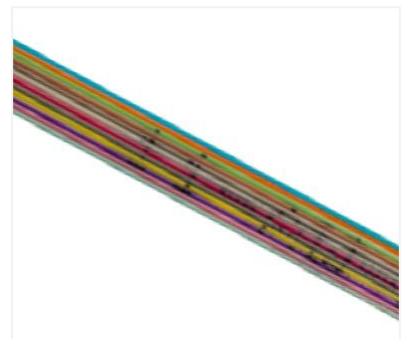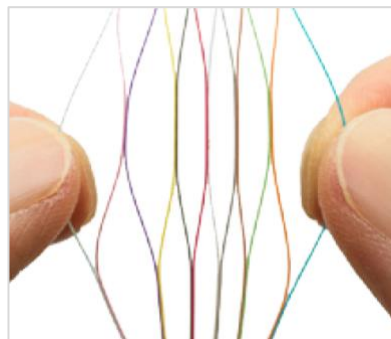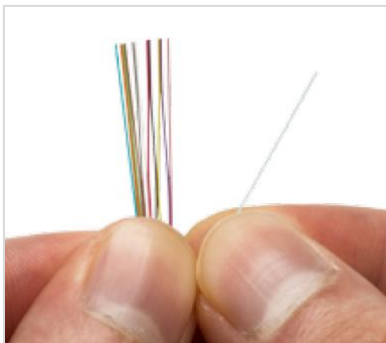

Ordering Information:

Please visit eCatalog at the link provided. [CLICK HERE](#)

Part Numbers

| ROLLABLE RIBBON FIBER CABLE PORTFOLIO | | |
|--|----------------------------|-------------------------------|
| Fiber Count | STANDARD LOOSE TUBE | |
| | Non-Armored | Armored |
| 432 | D-432-LN-RR-F12NS/8Z/99H | D-432-LA-RR-F12NS/8Z/99H |
| 576 | D-576-LN-RR-F12NS/8Z/99H | D-576-LA-RR-F12NS/8Z/99H |
| 864 | D-864-LN-RR-F12NS/8Z/99H | D-864-LA-RR-F12NS/8Z/99H |
| 1152 | D-1152-LN-RR-F12NS/8Z/99H | D-1152-LA-RR-F12NS/8Z/99H |
| 1440 | D-1440-LN-RR-F12NS/8Z/99H | D-1440-LA-RR-F12NS/8Z/99H |
| 1728 | D-1728-LN-RR-F12NS/8Z/99H | D-1728-LA-RR-F12NS/8Z/99H |
| 3456 | D-3456-LN-RR-F12NS/8Z/99H | NA |
| Fiber Count | CENTRAL TUBE | |
| | Non-Armored | Armored, Double Jacket |
| 144 | D-144-CN-RR-F12NS/8Z/99G | D-144-C2-RR-F12NS/8Z/99J |
| 288 | D-288-CN-RR-F12NS/8Z/99G | D-288-C2-RR-F12NS/8Z/99J |

Support Information:

Please contact your local CommScope representative for additional information.