


PS-R-CNTRL

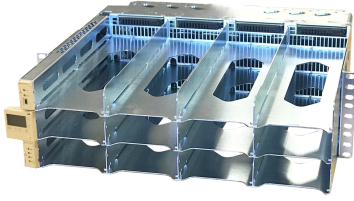

PowerShift® Rack and Module, accommodates up to 12 modules (2 separate circuits each for a total capacity of 12 RRU's with redundancy when all 12 modules are installed), includes controller Pulsar-Ede-C2

- Reduced capital/operating expenditures
- Engineering flexibility
- Future-ready design

Product Classification

Brand	PowerShift®
Product Series	V2
Product Type	Shelf

Dimensions

Depth	467.36 mm 18.40 in
Height	133.35 mm 5.25 in
Weight	13.15 kg 29.00 lb
Width	482.60 mm 19.00 in

General Specifications

Application	Mounts PowerShift® modules
Color	Silver metallic
Package Quantity	1
Rack Type	EIA 19 in
Rack Units	3
Shelf Movement	Fixed

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2011/65/EU	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



Included Products

Pulsar-Edge-C2 — PowerShift® High Power Pulsar Edge Controller with C2 software (included with shelf)

Pulsar-Edge-C2

PowerShift® High Power Pulsar Edge Controller with C2 software (included with shelf)



Product Classification

Brand	PowerShift®
Product Series	V2
Product Type	Module

Dimensions

Depth	345.44 mm 13.60 in
Height	41.40 mm 1.63 in
Width	18.29 mm 0.72 in

Electrical Specifications

Backplane Interfaces	10/100 Base-T Ethernet One Galaxy Protocol (GP) RS485 bus
Electrical Safety Standard	UL60950-UL/cUL with CB report
Front Panel Display	Interface to shelf mounted interactive display

Environmental Specifications

Ambient Temperature	65 °C -40 °C
Mean Time Between Failures (MTBF)	300000 h @ 25 °C
Relative Humidity	95%, non-condensing

General Specifications

Package Quantity	1
-------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2011/65/EU	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

