


## LSA-Plus® Backmount Frame, 19 in, 15-way, 3 RU, recessed

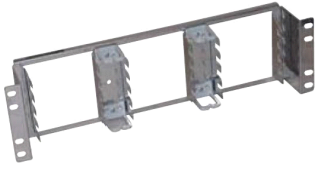

### Product Classification

<b>Brand</b>	LSA-PLUS®
<b>Product Series</b>	Highband
<b>Product Type</b>	Copper patch panel
<b>Regional Availability</b>	EMEA

### Dimensions

<b>Height</b>	133.35 mm   5.25 in
<b>Width</b>	482.60 mm   19.00 in

### General Specifications

<b>Application</b>	For use with LSA-PLUS modules
<b>Color</b>	Silver
<b>Growth Configuration</b>	Unloaded
<b>Interface, front</b>	LSA-PLUS module
<b>Modules, quantity</b>	15
<b>Package Quantity</b>	1
<b>Packaging Type</b>	Bag   Box
<b>Rack Type</b>	EIA 19 in
<b>Rack Units</b>	3.0

### Mechanical Specifications

<b>Panel Style</b>	Straight
<b>Material Type</b>	High-impact, flame retardant, thermoplastic   Steel
<b>Panel Mounting</b>	Flush

### Regulatory Compliance/Certifications

**Agency**  
RoHS 2011/65/EU

**Classification**  
Compliant

