


Copper Cable, Category 6, U/UTP, 23 AWG, CM, Reel in a box, 1000 ft, blue

Product Classification

Portfolio	NETCONNECT®
Product Type	Twisted pair cable
Regional Availability	Asia Australia/New Zealand

Cross Section Drawing

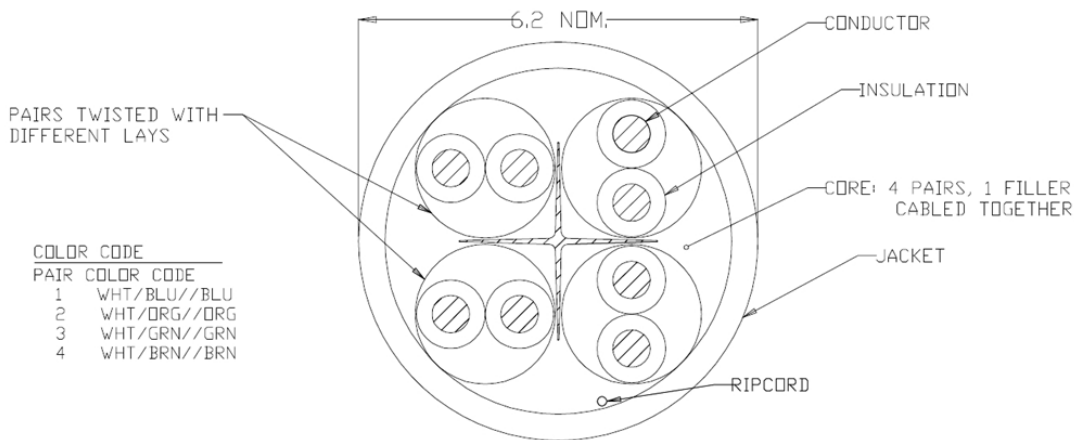

Construction Materials

Jacket Material	PVC
Conductor Material	Bare copper

Dimensions

Cable Length	305 m 1000 ft
Diameter Over Jacket, nominal	6.400 mm 0.252 in

Electrical Specifications

ANSI/TIA Category	6
Operating Voltage, maximum	80 V
Transmission Standards	ANSI/TIA-568-C.2 ISO/IEC 11801 Class E

Environmental Specifications

Flame Test Method	CM IEC 60332-1
--------------------------	------------------

General Specifications

Cable Type	U/UTP (unshielded)
Packaging Type	Reel in box
Pairs, quantity	4
Cable Component Type	Horizontal
Jacket Color	Blue
Conductor Gauge, singles	23 AWG
Conductor Type, singles	Solid
Conductors, quantity	8

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

