


Copper Cable, Category 6, U/UTP, 23 AWG, CM, Reelspeed, 1000 ft, gray

## Product Classification

<b>Portfolio</b>	NETCONNECT®
<b>Product Type</b>	Twisted pair cable
<b>Regional Availability</b>	Asia   Australia/New Zealand

## Cross Section Drawing

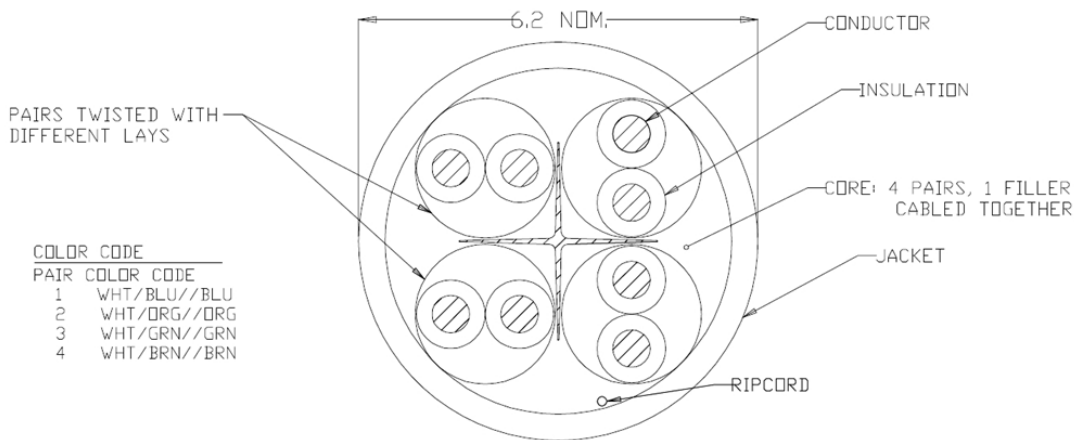

## Construction Materials

<b>Jacket Material</b>	PVC
<b>Conductor Material</b>	Bare copper

## Dimensions

<b>Cable Length</b>	305 m   1000 ft
<b>Diameter Over Jacket, nominal</b>	6.400 mm   0.252 in

## Electrical Specifications

**ANSI/TIA Category** 6  
**Operating Voltage, maximum** 80 V  
**Transmission Standards** ANSI/TIA-568-C.2 | ISO/IEC 11801 Class E

## Environmental Specifications

**Flame Test Method** CM | IEC 60332-1

## General Specifications

**Cable Type** U/UTP (unshielded)  
**Packaging Type** Reel  
**Pairs, quantity** 4  
**Cable Component Type** Horizontal  
**Jacket Color** Gray  
**Conductor Gauge, singles** 23 AWG  
**Conductor Type, singles** Solid  
**Conductors, quantity** 8

## Regulatory Compliance/Certifications

**Agency**  
RoHS 2011/65/EU

**Classification**  
Compliant

