


Qwik II Connector™, SC, SM-APC, Green, for 250/900um, 25 per pack

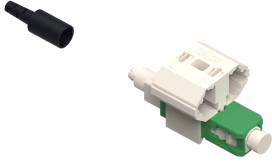

## Product Classification

<b>Portfolio</b>	CommScope®
<b>Brand</b>	Qwik   TeraSPEED®
<b>Product Series</b>	Qwik II
<b>Product Type</b>	Fiber connector
<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America

## Construction Materials

<b>Fiber Type</b>	OS2
<b>Ferrule Geometry</b>	Factory polished
<b>Ferrule Material</b>	Zirconia
<b>Fiber Mode</b>	Singlemode

## Dimensions

<b>Compatible Cable Diameter, maximum</b>	0.90 mm   0.04 in
<b>Compatible Cable Diameter, minimum</b>	0.25 mm   0.01 in
<b>Length</b>	42.60 mm   1.68 in

## General Specifications

<b>Interface</b>	SC
<b>Body Style</b>	BTW
<b>Interface Feature</b>	APC   Field Installable   Mechanical splice
<b>Color</b>	Green
<b>Color, boot</b>	Black
<b>Package Quantity</b>	25

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	1.00 lb @ 0 °
--	---------------

## Optical Performance

<b>Insertion Loss, typical</b>	0.30 dB
--------------------------------	---------

**Return Loss, minimum** 50.0 dB

## Optical Specifications

**Optical Components Standard** ANSI/TIA-568. 3-D

## Regulatory Compliance/Certifications

### Agency

RoHS 2011/65/EU  
ISO 9001:2015

### Classification

Compliant  
Designed, manufactured and/or distributed under this quality management system

