


Qwik II Connector™, LC, OM3/4/5, Aqua, for 250/900um, 25 per pack

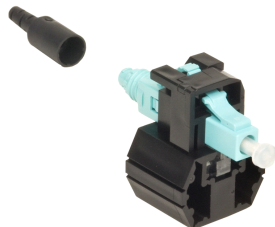

Product Classification

Portfolio	CommScope®
Brand	LazrSPEED® Qwik
Product Series	Qwik II
Product Type	Fiber connector
Regional Availability	Asia Australia/New Zealand EMEA Latin America North America

Construction Materials

Fiber Type	OM3 OM4 OM5, LazrSPEED® wideband
Ferrule Geometry	Factory polished
Ferrule Material	Zirconia
Fiber Mode	Multimode

Dimensions

Compatible Cable Diameter, maximum	0.90 mm 0.04 in
Compatible Cable Diameter, minimum	0.25 mm 0.01 in
Length	42.60 mm 1.68 in

General Specifications

Interface	LC
Body Style	BTW
Interface Feature	Field Installable Mechanical splice
Color	Aqua
Color, boot	Black
Package Quantity	25

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 °
--	---------------

Optical Performance

Insertion Loss, typical	0.27 dB
Return Loss, minimum	20.0 dB

Optical Specifications

Optical Components Standard	ANSI/TIA-568. 3-D
------------------------------------	-------------------

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2011/65/EU	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

