


Qwik II Connector™, LC, OM1, Beige, for 250/900um, 25 per pack

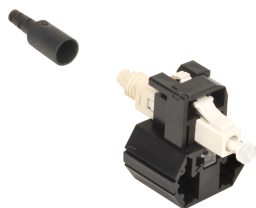

Product Classification

| | |
|------------------------------|---|
| Portfolio | CommScope® |
| Brand | OptiSPEED® Qwik |
| Product Series | Qwik II |
| Product Type | Fiber connector |
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |

Construction Materials

| | |
|-------------------------|------------------|
| Fiber Type | OM1 |
| Ferrule Geometry | Factory polished |
| Ferrule Material | Zirconia |
| Fiber Mode | Multimode |

Dimensions

| | |
|---|--------------------|
| Compatible Cable Diameter, maximum | 0.90 mm 0.04 in |
| Compatible Cable Diameter, minimum | 0.25 mm 0.01 in |
| Length | 42.60 mm 1.68 in |

General Specifications

| | |
|--------------------------|---------------------------------------|
| Interface | LC |
| Body Style | BTW |
| Interface Feature | Field Installable Mechanical splice |
| Color | Beige |
| Color, boot | Black |
| Package Quantity | 25 |

Mechanical Specifications

| | |
|--|---------------|
| Cable Retention Strength, maximum | 1.00 lb @ 0 ° |
|--|---------------|

Optical Performance

Insertion Loss, typical 0.27 dB
Return Loss, minimum 20.0 dB

Optical Specifications

Optical Components Standard ANSI/TIA-568. 3-D

Regulatory Compliance/Certifications

| Agency | Classification |
|-----------------|--|
| RoHS 2011/65/EU | Compliant |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |

