


Qwik II Connector™, SC, SM-UPC, Blue, for 250/900um, 25 per pack

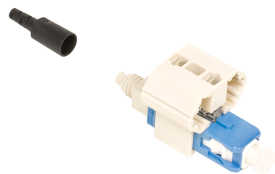

Product Classification

Portfolio	CommScope®
Brand	Qwik TeraSPEED®
Product Series	Qwik II
Product Type	Fiber connector
Regional Availability	Asia Australia/New Zealand EMEA Latin America North America

Construction Materials

Fiber Type	OS2
Ferrule Geometry	Factory polished
Ferrule Material	Zirconia
Fiber Mode	Singlemode

Dimensions

Compatible Cable Diameter, maximum	0.90 mm 0.04 in
Compatible Cable Diameter, minimum	0.25 mm 0.01 in
Length	50.20 mm 1.98 in

General Specifications

Interface	SC
Body Style	BTW
Interface Feature	Field Installable Mechanical splice UPC
Color	Blue
Color, boot	Black
Package Quantity	25

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 °
--	---------------

Optical Performance

Insertion Loss, typical 0.30 dB
Return Loss, minimum 45.0 dB

Optical Specifications

Optical Components Standard ANSI/TIA-568. 3-D

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2011/65/EU	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

