


HomeConnect® F Type Right Angle Connector

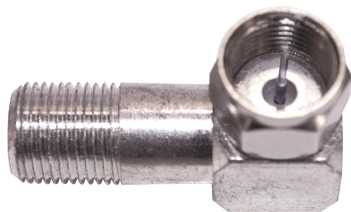

OBSOLETE

Product Classification

Brand	HomeConnect®
Product Type	Wireless and radiating connector

Environmental Specifications

Safety Standard	CE EN 60728-4 SCTE
------------------------	------------------------

Electrical Specifications

Impedance	75 ohm
Insertion Loss, maximum	0.50 dB
Operating Frequency Band	0 – 1002 MHz
Return Loss, minimum	30 dB

General Specifications

Device Type	Connector
--------------------	-----------

Mechanical Specifications

Material Type	Brass
Plating	Nickel

Packed Dimensions

Carton Quantity	1500
Height	190.50 mm 7.50 in
Length	330.20 mm 13.00 in
Width	241.30 mm 9.50 in
Shipping Weight	26.31 kg 58.00 lb

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

