


## HomeConnect® F Type Port Non-locking Terminator, brass

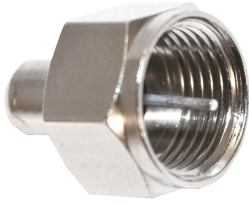

### Product Classification

<b>Brand</b>	HomeConnect®
<b>Product Type</b>	Terminator

### Environmental Specifications

<b>Operating Temperature</b>	-40 °C to +60 °C (-40 °F to +140 °F)
<b>Safety Standard</b>	CE   EN 60728-4   SCTE

### Electrical Specifications

<b>Impedance</b>	75 ohm
<b>Operating Frequency Band</b>	5 – 2000 MHz
<b>Return Loss at Frequency Band, minimum</b>	20 dB @ 1700–2000 MHz   24 dB @ 1002–1700 MHz   25 dB @ 1002–1500 MHz   30 dB @ 5–1002 MHz
<b>Shielding Effectiveness, minimum</b>	100 dB

### General Specifications

<b>Device Type</b>	Non-locking terminator
<b>Parking Port</b>	Not included

### Dimensions

<b>Contact Pin Diameter</b>	0.813 mm   0.032 in
-----------------------------	---------------------

### Mechanical Specifications

<b>Material Type</b>	Brass
<b>Plating</b>	Nickel

### Packed Dimensions

<b>Carton Quantity</b>	5000
<b>Height</b>	190.50 mm   7.50 in

# CSF59T

---

<b>Length</b>	330.20 mm   13.00 in
<b>Width</b>	241.30 mm   9.50 in
<b>Shipping Weight</b>	19.05 kg   42.00 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
RoHS 2011/65/EU	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

