



## AMPINNERGY® Power Entry Cable Assembly, 8-wire/4-circuit (4-2-2), shared neutral, 10 feet

- Used to interface between manufactured wiring and other wiring systems, such as building wiring, fixture wiring, or access floor module wiring
- Mates to line connector cable assemblies, power junction boxes, power distribution modules (PDMs), zone distribution modules (ZDBs) and power transition units (PTUs)

### Product Classification

|                              |                            |
|------------------------------|----------------------------|
| <b>Brand</b>                 | AMPINNERGY®                |
| <b>Product Series</b>        | AMPINNERGY                 |
| <b>Product Type</b>          | Power entry cable assembly |
| <b>Regional Availability</b> | North America              |

### Dimensions

|                                 |                   |
|---------------------------------|-------------------|
| <b>Cord Length</b>              | 3.05 m   10.00 ft |
| <b>Exposed Conductor Length</b> | 12.00 in          |

### Electrical Specifications

|                                |                         |
|--------------------------------|-------------------------|
| <b>Current Rating, maximum</b> | 20.00 A                 |
| <b>Voltage Rating, maximum</b> | 125.00 Vac   250.00 Vac |

### Environmental Specifications

|                            |  |
|----------------------------|--|
| <b>Environmental Space</b> | Indoor   |
| <b>Safety Standard</b>     | CEC 2015   CSA 22.2   NEC 2013   UL 1286   UL 183   UL 498 |


### General Specifications

|                                       |                       |
|---------------------------------------|-----------------------|
| <b>Application</b>                    | Line entry connection |
| <b>Construction Type</b>              | Corrugated hose       |
| <b>Interface, connector A</b>         | Power male plug       |
| <b>Interface, connector B</b>         | Unterminated          |
| <b>Neutral Conductor Gauge, solid</b> | 10-12 AWG             |
| <b>Neutral Type</b>                   | Shared                |
| <b>Package Quantity</b>               | 1                     |
| <b>Packaging Type</b>                 | Bag                   |

### Mechanical Specifications

|               |                          |
|---------------|--------------------------|
| <b>Wiring</b> | 8-Wire/4 Circuit (4-2-2) |
|---------------|--------------------------|

## Outline Drawing

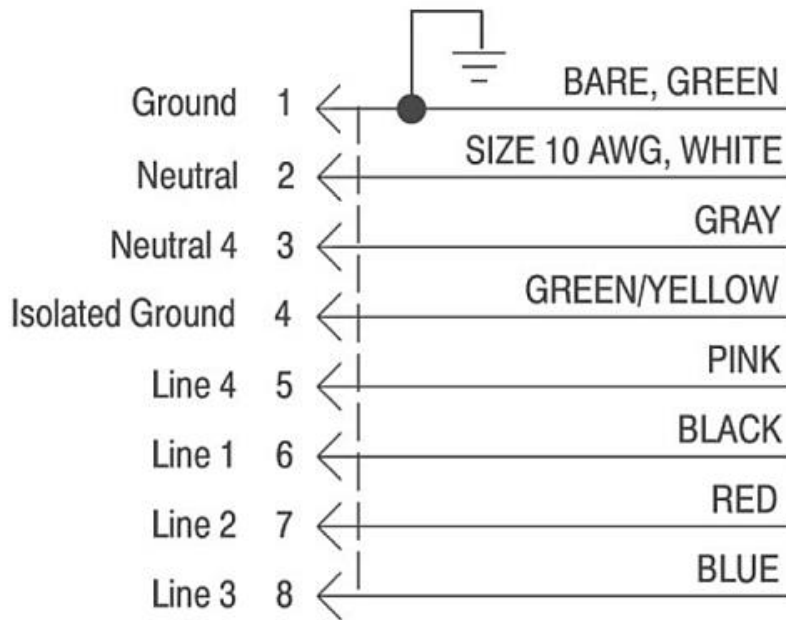

Outline Drawing

Used as an image placeholder

## Regulatory Compliance/Certifications

### Agency

RoHS 2011/65/EU

### Classification

Compliant

