


Universal Snap-in Hanger for 5/8 in corrugated coaxial cable

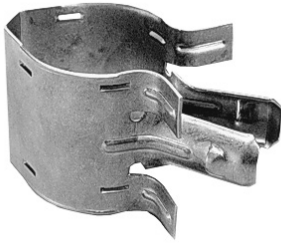

OBSOLETE

This product was discontinued on: **December 31, 2018**

Replaced By

SSH-M

SnapStak® Plus Adjustable Hanger for 14mm to 25mm Cable - No Grommets Required. For patents, see www.cs-pat.com.

Product Classification

Product Type Hanger kit

Dimensions

Nominal Size	5/8 in
Compatible Diameter, maximum	22.022 mm 0.867 in
Compatible Diameter, minimum	20.828 mm 0.820 in
Height	41.00 mm 1.61 in
Length	56.00 mm 2.20 in
Width	36.30 mm 1.43 in

Electrical Specifications

DTF Effect	0.1 dB
Return Loss Effect	0.1 dB

Environmental Specifications

Operating Temperature -40 °C to +85 °C (-40 °F to +185 °F)

General Specifications

Hanger Type	Snap-in hanger
Cable Type	Corrugated
Cables per Hanger	1
Color	Silver

206706A-6

Material Type	Stainless steel
Ordering Note	CommScope® non-standard product
Package Quantity	10

Mechanical Specifications

Corrosion Resistance, minimum with no degradation	≥500 hours in salt spray chamber
Mounting	3/4 in through hole
Vibration Survival	≥4 hours at resonant frequency
Environmental Strength Capability	Double cable weight

Packed Dimensions

Height	17.0 cm 6.7 in
Length	10.0 cm 3.9 in
Shipping Weight	0.35 kg 0.78 lb
Width	13.0 cm 5.1 in

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

