

# BSAMNT-SBS-1-2

---

Side-By-Side Mounting Kit to mount two antennas on a pipe with 2.375 - 4.5 inch (60 – 115 mm) diameter

- Supports SBNHH and NHH 65° and 85° antennas

## General Specifications

<b>Application</b>	Outdoor
<b>Includes</b>	Brackets   Hardware
<b>Package Quantity</b>	1

## Mechanical Specifications

<b>Color</b>	Silver
<b>Material Type</b>	Galvanized steel

## Dimensions

<b>Compatible Diameter, maximum</b>	114.3 mm   4.5 in
<b>Compatible Diameter, minimum</b>	61.0 mm   2.4 in
<b>Net Weight</b>	11.5 kg   25.4 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
RoHS 2011/65/EU	Compliant by Exemption
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
China RoHS SJ/T 11364-2014	Above Maximum Concentration Value (MCV)




## Included Products

BSAMNT-4 — Wide Profile Antenna Downtilt Mounting Kit for 2.4 - 4.5 in (60 - 115 mm) OD round members. Kit contains one scissor top bracket set and one bottom bracket set.

# BSAMNT-4

---

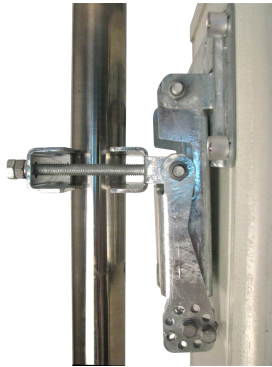

Wide Profile Antenna Downtilt Mounting Kit for 2.4 - 4.5 in (60 - 115 mm) OD round members. Kit contains one scissor top bracket set and one bottom bracket set.

## General Specifications

<b>Application</b>	Outdoor
<b>Includes</b>	Brackets   Hardware
<b>Package Quantity</b>	1

## Mechanical Specifications

<b>Color</b>	Silver
<b>Material Type</b>	Galvanized steel

## Dimensions

<b>Compatible Diameter, maximum</b>	115.0 mm   4.5 in
<b>Compatible Diameter, minimum</b>	60.0 mm   2.4 in
<b>Net Weight</b>	6.6 kg   14.6 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
RoHS 2011/65/EU	Compliant by Exemption
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
China RoHS SJ/T 11364-2014	Above Maximum Concentration Value (MCV)

