


MTC401548HC

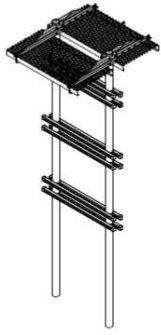

H-Frame with Ice Canopy, 4ft long with 2 Posts

Product Classification

Product Type Ice canopies and shields

Dimensions

Height 4076.7 mm | 160.5 in
Length 1219.2 mm | 48.0 in
Weight 162.5 kg | 358.3 lb
Width 1460.5 mm | 57.5 in

General Specifications

Includes Hardware | Ice shield | Legs | Unistrut
Material Type Hot dip galvanized steel
Package Quantity 1

Outline Drawing


Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



Included Products

 MF-130 — Direct Burial Pipe Column, 13 ft 4 in



Direct Burial Pipe Column, 13 ft 4 in

Product Classification

Product Type Pipe column

Dimensions

Height 4064.0 mm | 160.0 in

Length 88.9 mm | 3.5 in

Pipe Outer Diameter 88.9 mm | 3 1/2 in

Weight 45.8 kg | 101.0 lb

General Specifications

Application Direct burial

Includes Anchors | Pipe

Material Type Hot dip galvanized steel


Mounting Waveguide bridge support bracket

Package Quantity 1

Pipe Length 4.1 m | 13.3 ft

Pipe, quantity 1

Outline Drawing

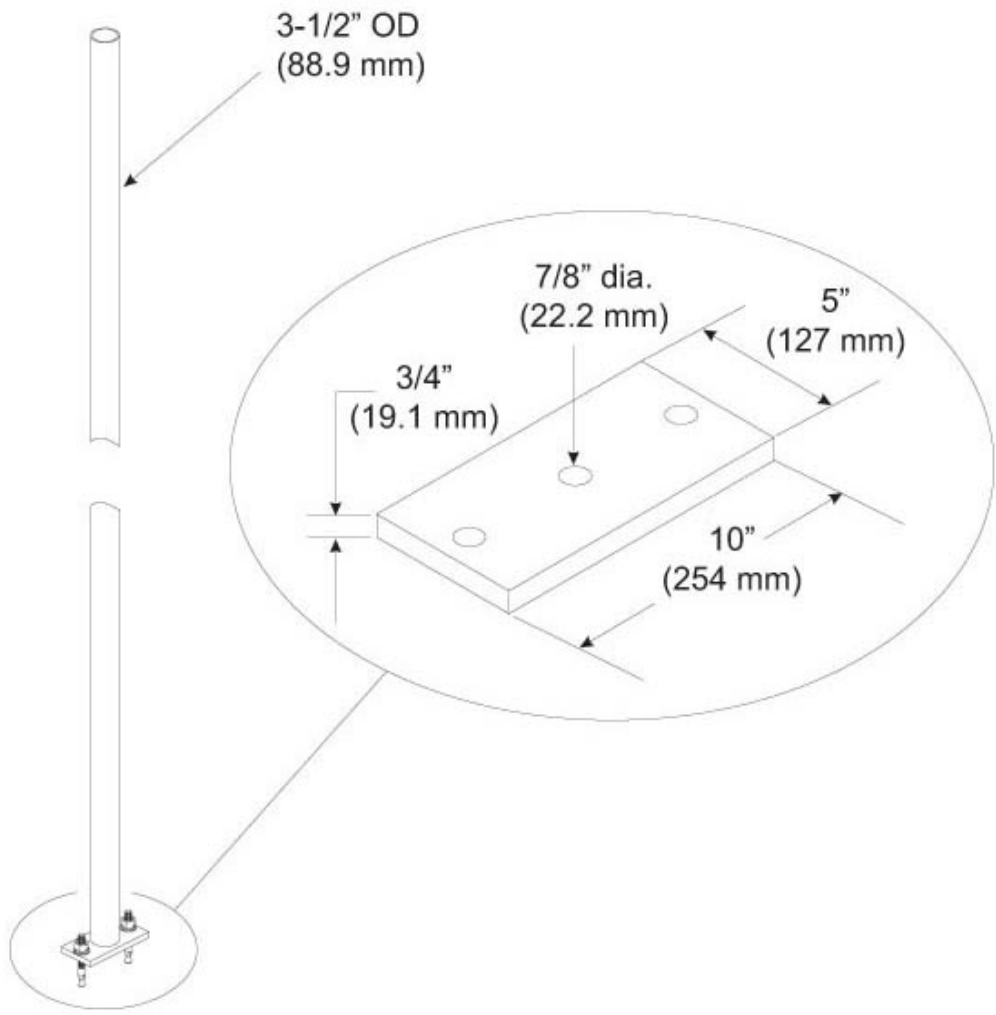

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

