


MTC401596HC

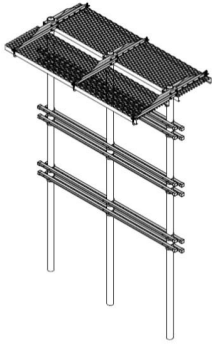

H-Frame with Ice Canopy, 8ft long with 3 Posts

Product Classification

Product Type Ice canopies and shields

Dimensions

Height 4064.0 mm | 160.0 in
Length 2438.4 mm | 96.0 in
Weight 255.3 kg | 562.9 lb
Width 1397.0 mm | 55.0 in

General Specifications

Includes Hardware | Ice shield | Legs | Unistrut
Material Type Hot dip galvanized steel
Package Quantity 1

Outline Drawing


Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |



Included Products

 MF-130 — Direct Burial Pipe Column, 13 ft 4 in



Direct Burial Pipe Column, 13 ft 4 in

Product Classification

Product Type Pipe column

Dimensions

Height 4064.0 mm | 160.0 in

Length 88.9 mm | 3.5 in

Pipe Outer Diameter 88.9 mm | 3 1/2 in

Weight 45.8 kg | 101.0 lb

General Specifications

Application Direct burial

Includes Anchors | Pipe

Material Type Hot dip galvanized steel


Mounting Waveguide bridge support bracket

Package Quantity 1

Pipe Length 4.1 m | 13.3 ft

Pipe, quantity 1

Outline Drawing

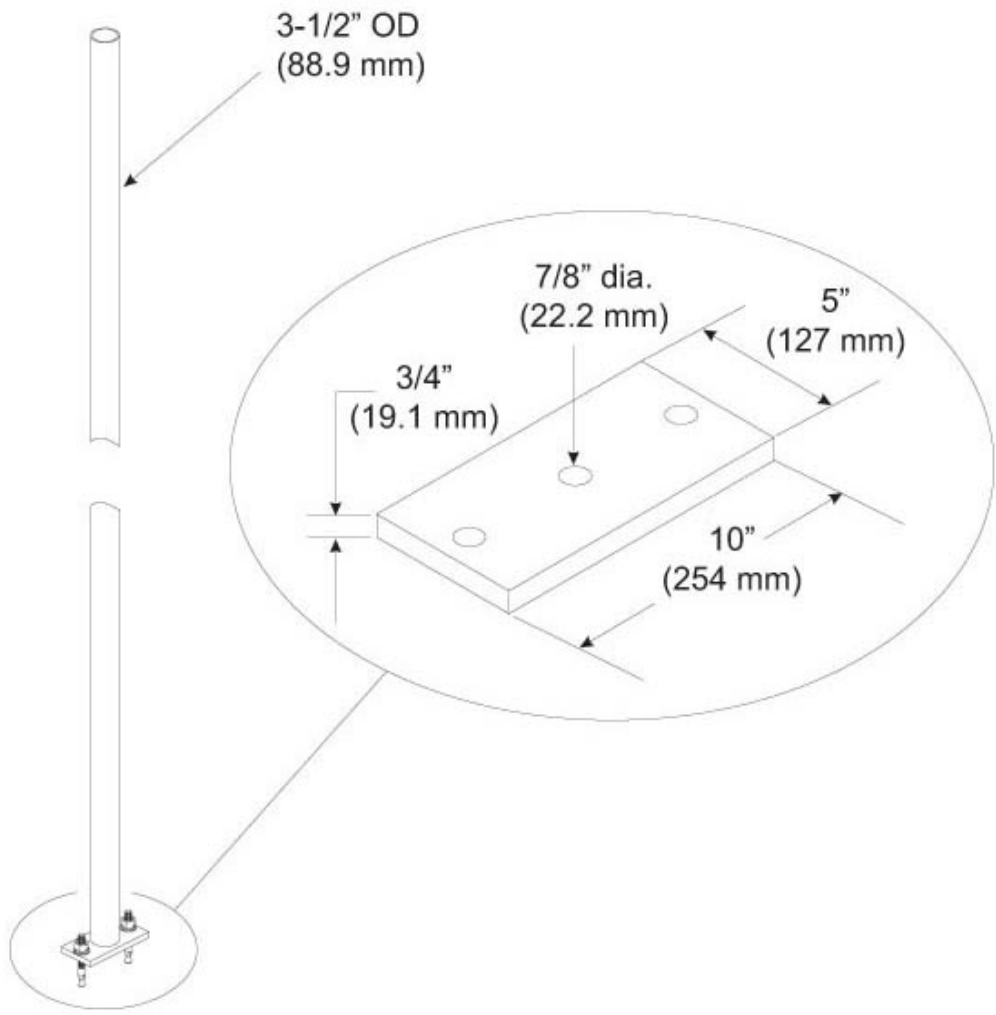

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

