


# MTC4015120H

---

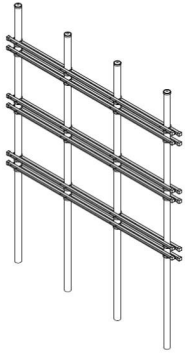

H-Frame, 10ft long with 4 Posts (no ice canopy)

## Product Classification

**Product Type** Ice canopies and shields

## Dimensions

**Height** 4064.0 mm | 160.0 in  
**Length** 3048.0 mm | 120.0 in  
**Weight** 265.1 kg | 584.5 lb  
**Width** 177.8 mm | 7.0 in

## General Specifications

**Includes** Hardware | Legs | Unistrut  
**Material Type** Hot dip galvanized steel  
**Package Quantity** 1

## Outline Drawing

 
## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



## Included Products

MF-130 — Direct Burial Pipe Column, 13 ft 4 in



Direct Burial Pipe Column, 13 ft 4 in

## Product Classification

**Product Type** Pipe column

## Dimensions

**Height** 4064.0 mm | 160.0 in

**Length** 88.9 mm | 3.5 in

**Pipe Outer Diameter** 88.9 mm | 3 1/2 in

**Weight** 45.8 kg | 101.0 lb

## General Specifications

**Application** Direct burial

**Includes** Anchors | Pipe

**Material Type** Hot dip galvanized steel


**Mounting** Waveguide bridge support bracket

**Package Quantity** 1

**Pipe Length** 4.1 m | 13.3 ft

**Pipe, quantity** 1

## Outline Drawing

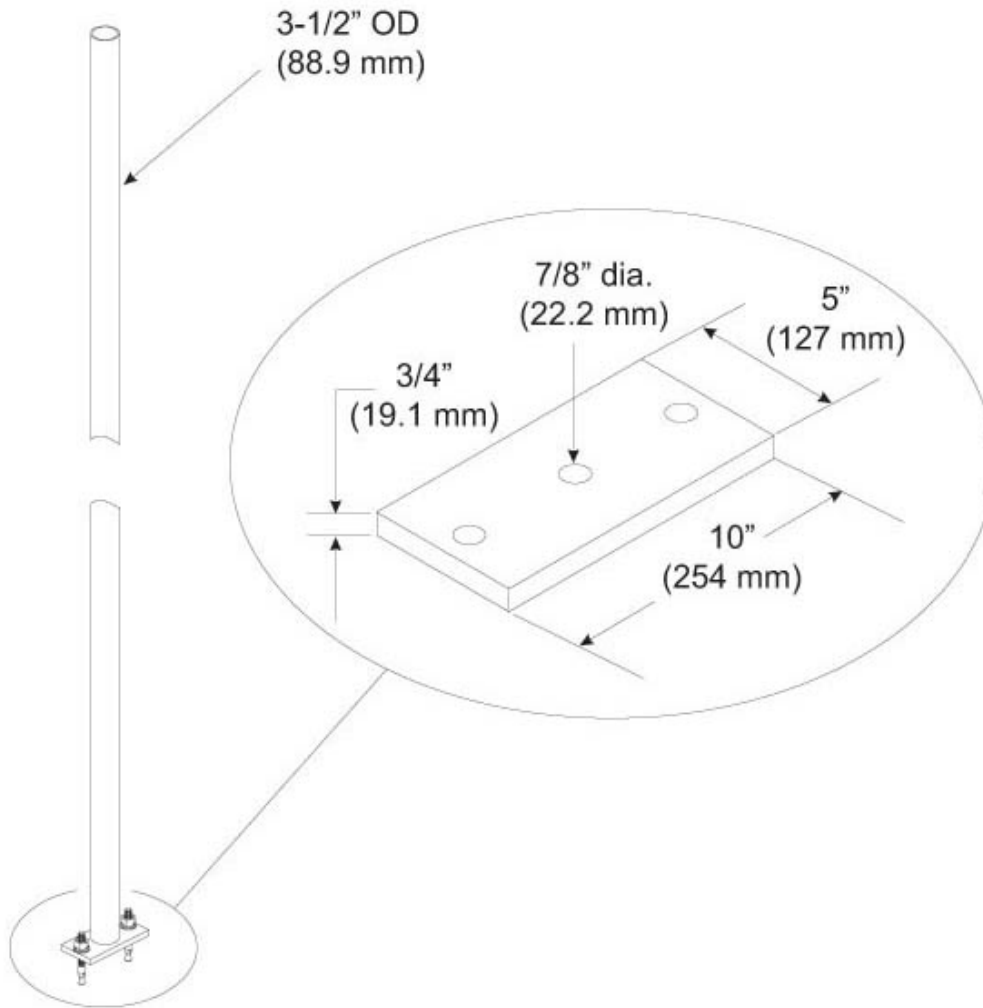

## Regulatory Compliance/Certifications

**Agency**

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system

