


Cable Banding, Bulk, 1/2 in x 50 ft Reel (uses CB-LH-25 Locking Heads - not incl)

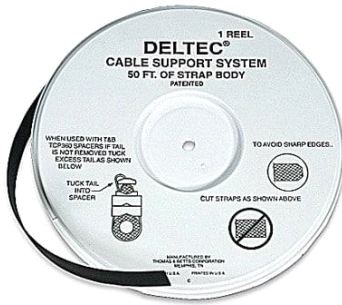

Product Classification

Product Type Banding

Dimensions

Length 15.24 m | 50.00 ft

Width 12.70 mm | 0.50 in

Environmental Specifications

Operating Temperature -65 °C to +90 °C (-85 °F to +194 °F)

General Specifications

Adapter Type Adapter

Color Black

Material Type Heat-stabilized weather resistant acetal

Ordering Note CommScope® standard product in the United States and Canada

Package Quantity 1

Mechanical Specifications

Material Thickness 1.520 mm | 0.060 in

Mounting Round member

Regulatory Compliance/Certifications

Agency **Classification**

CSA

RoHS 2011/65/EU

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

