


PM-SC3-96

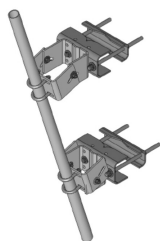

Universal Open Face Pipe Mount Kit, includes 2-7/8 in OD x 96 in pipe

Product Classification

Product Type Pipe mount

General Specifications

Mounting	Angle 60°, 203.2 mm (8 in) Angle 90°, 152.4 mm (6 in) Straight or tapered legs up to 203.2 mm (8 in) OD
Note	One 96 in x 8 in panel antenna per sector
Pipe, quantity	1
Tower Taper	Non-tapered Tapered

Dimensions

Height	2,438.4 mm 96 in
Width	304.8 mm 12 in
Length	304.8 mm 12 in
Pipe Length	2,438.4 mm 96 in
Mounting Diameter, maximum	203.2 mm 8 in
Mounting Diameter, minimum	0 mm 0 in
Pipe Outer Diameter	73.66 mm 2.9 in
Stand-off Distance	203.2 mm 8 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating	120 mph (BWS) at 150 ft AGL
Wind Rating Test Method	TIA/EIA-222

Packaging and Weights

PM-SC3-96

Included	Pipe Sliding pipe mount brackets Universal saddle mount
Packaging quantity	1
Weight, net	68.7 kg 151.457 lb

* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--