


# CL-0220-U

---

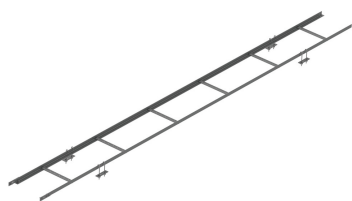

Universal Cable Ladder Kit, 20 ft, 2-hole rung

## Product Classification

**Product Type** Ladder kit

## General Specifications

**Cable Runs, quantity** 2  
**Mounting** Round and angle legs

## Dimensions

**Length** 6096 mm | 240 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Attachment kits | Ladder | Splice plates  
**Packaging quantity** 1  
**Weight, net** 32.9 kg | 72.532 lb

## Included Products

HK-CL-U – Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

# HK-CL-U



Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

## Product Classification

Product Type	Ladder kit
Ordering Note	ANDREW® standard product (Global)

## General Specifications

Cable Runs, quantity	0
Mounting	Round and angle legs

## Dimensions

Height	203.2 mm   8 in
Width	127 mm   5 in
Length	203.2 mm   8 in
Mounting Diameter, maximum	114.3 mm   4.5 in
Mounting Diameter, minimum	25.4 mm   1 in

## Material Specifications

Material Type	Hot dip galvanized steel
---------------	--------------------------

## Packaging and Weights

Included	J-bolts   Plates
Packaging quantity	1
Weight, net	1.7 kg   3.748 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted

# HK-CL-U

---

UK-ROHS

Compliant/Exempted

