


# UNGLULUT8

Base Product

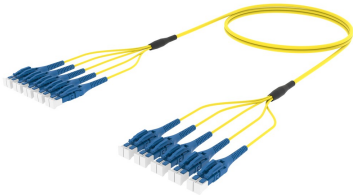

Singlemode LC/UPC Uniboot to LC/UPC Uniboot Ruggedized fanout Cable, 8-Fiber, Dual Rated LSZH/Riser, 8 fiber PmP 2.0 mm

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	Propel   SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Connector A, quantity</b>	4
<b>Color, boot A</b>	Blue
<b>Color, connector A</b>	Blue
<b>Connector B, quantity</b>	4
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	LC/UPC
<b>Interface Feature, connector A</b>	Uniboot
<b>Interface, Connector B</b>	LC/UPC
<b>Interface Feature, connector B</b>	Uniboot
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	8


## Dimensions

# UNGLULUT8

**Cable Assembly Length Range (m)** 3 – 999

**Cable Assembly Length Range (ft)** 8 – 999

## Ordering Tree

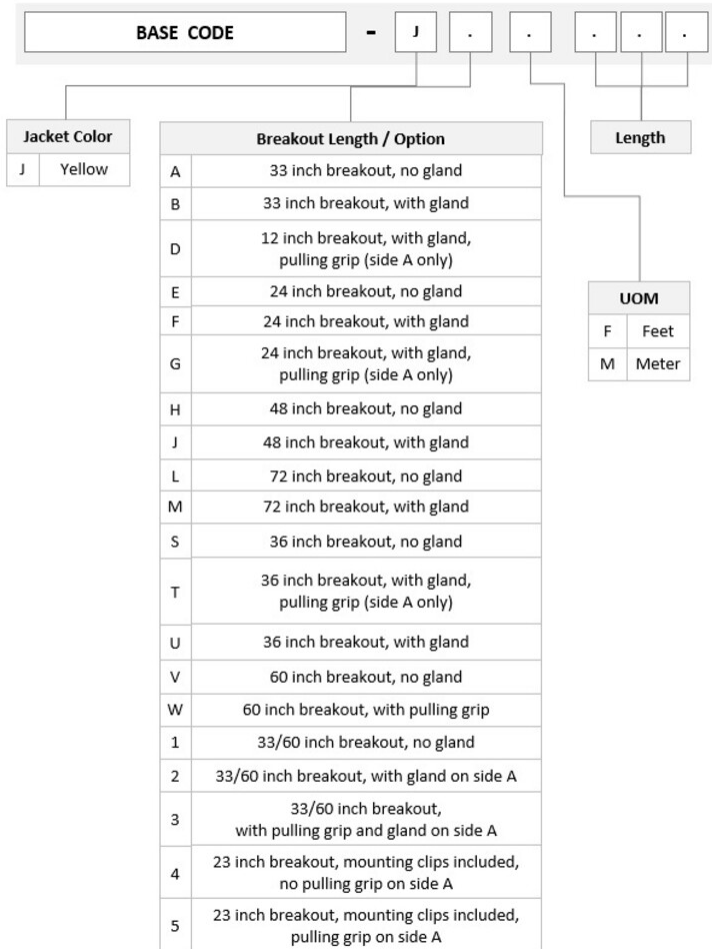

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

# UNGLULUT8

---

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

760245569	-	Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk with 2.0mm Subunits, 8 fiber,
N-008-MP-8G1-F08YL/20T/D		Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating
860658160	-	LC/UPC Uniboot Connector, Singlemode, Blue