


UPGLCUCCL

Base Product

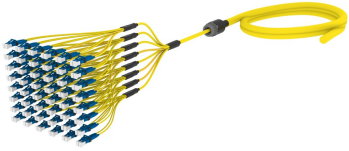

Ultra Low Loss (ULL) Singlemode LC/UPC to Unconnectorized Armored Pre-terminated Trunk Cable, 96-Fiber, Dual Rated LSZH/Riser

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Ruggedized fanout

Product Brand

SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	96
Color, boot A	Blue
Color, connector A	Blue
Construction Type	Ultra Low Loss (ULL) armored trunk/extension/cross-connect, indoor
Furcation Color	Yellow
Interface, Connector A	LC/UPC
Interface, Connector B	Unterminated
Jacket Color	Yellow
Total Fibers, quantity	96

Dimensions

Cable Assembly Length Range (m)	7 – 999
Cable Assembly Length Range (ft)	25 – 999

Ordering Tree

UPGLCUCL

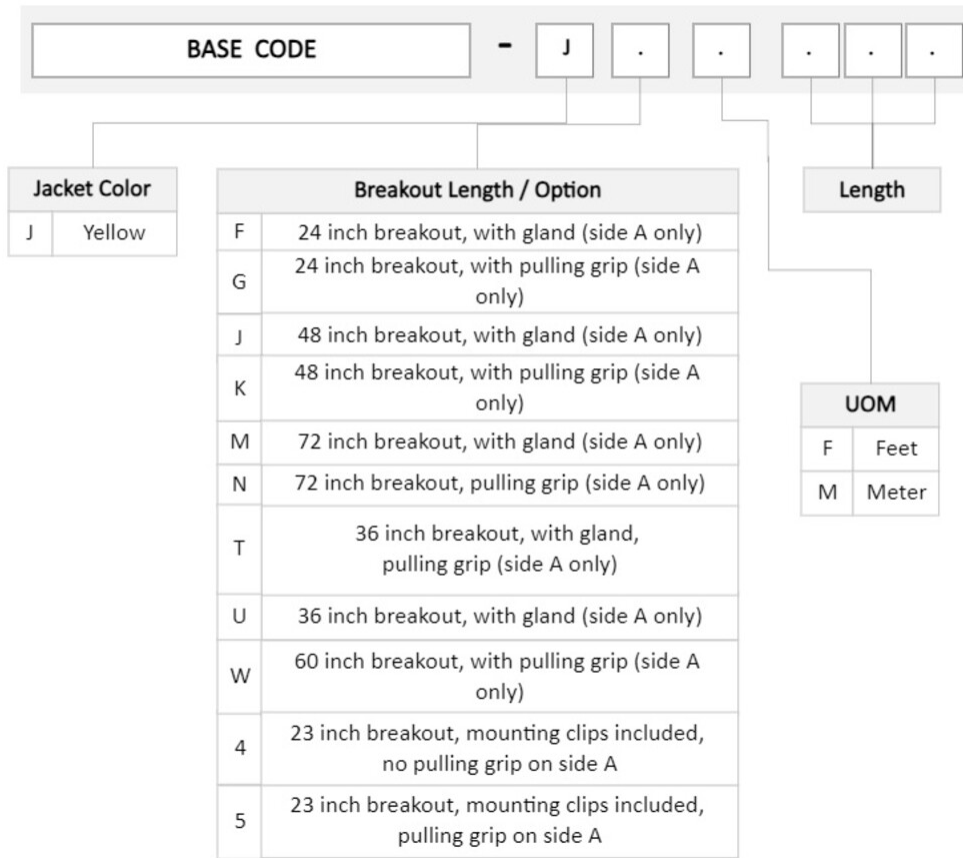

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Dual Rated LSZH/Riser Indoor

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

UPGLCUCCL

Included Products

- 760256105
N-096-MZ-8G1-F12YL/20T/B2 – Fiber indoor cable, Riser/LSZH rated MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 96 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860637435 – LC/UPC Connector, Singlemode, Blue, Short Boot