

# D3GQYQYVP

Base Product

Ultra Low Loss (ULL) Singlemode MPO8 QSFP Pinned with Push-Pull Boot to MPO8 QSFP Pinned with Push-Pull Boot, Fiber Trunk Cable Assembly, 288-Fiber, Dual Rated LSZH/Riser B2ca

## Product Classification

Regional Availability	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Color, boot A	Black
Color, connector A	Yellow
Color, boot B	Black
Color, connector B	Yellow
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Male
Interface Feature, connector A	Key up/down
Interface Body Style, connector A	Push-pull boot
Interface, Connector B	MPO-08/APC Male
Interface Feature, connector B	Key up/down
Interface Body Style, connector B	Push-pull boot
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	288


## Dimensions

Cable Assembly Length Range (m)	2 – 999
---------------------------------	---------

# D3GQYQYVP

Cable Assembly Length Range (ft)7 – 999

## Ordering Tree

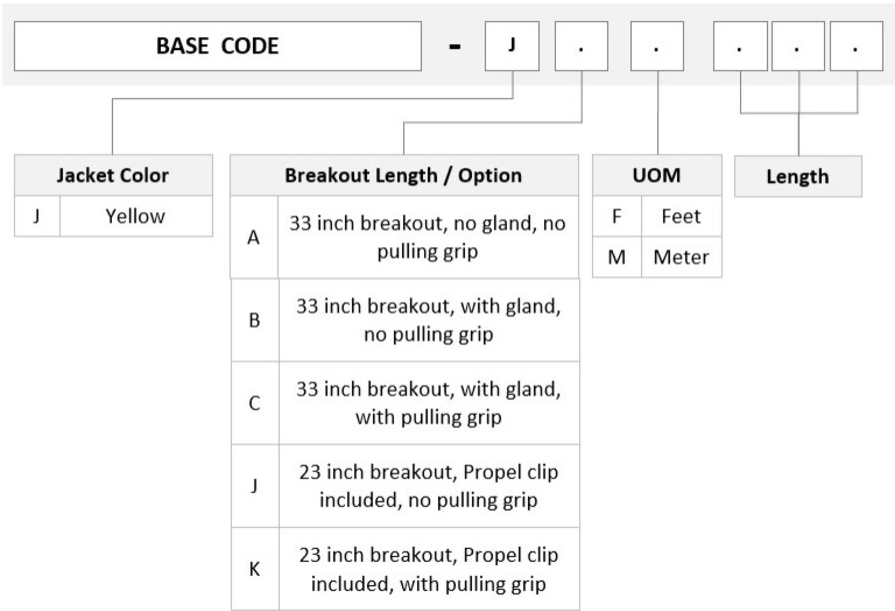

## Mechanical Specifications

Cable Retention Strength, maximum11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

Fiber ModeSinglemode

Fiber TypeG.657.A2, TeraSPEED®

## Environmental Specifications

Operating Temperature-10 °C to +60 °C (+14 °F to +140 °F)

EN50575 CPR Cable EuroClass Fire PerformanceB2ca

Environmental SpaceDual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

# D3GQYQYVP

REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



## Included Products

460202379	-	MP08/12 ULL Male, Singlemode, Yellow, Push-Pull, 3mm
760249612	-	Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 288 fiber with 2.0 mm Subunits, Singlemode G.657.A2, Feet jacket marking, Yellow jacket color, B2ca flame rating
N-288-MP-8G1-F12YL/20T/B2		