


# FD3-MN360J00M0ME0B

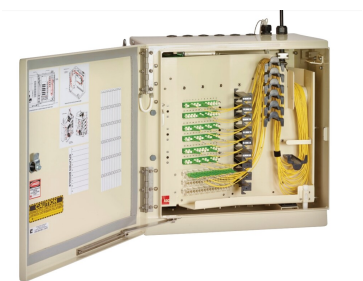

Indoor FDH 3000 w/ 432f Shell, 360f distribution loaded, no splitters included, MPO distribution connectors, and a 24f Feeder using Spliced Stranded Loose Tube Pigtailes

Indoor FDH 3000 w/ 432f Shell, 360f distribution loaded, no splitters included, MPO distribution connectors, and a 24f Feeder using Spliced Stranded Loose Tube Pigtailes

## Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	IFDH 3000

## General Specifications

Functionality	Patching   Splicing
Adapters, quantity	360
Color	Putty white
Front Door Type	Single hinged
Interface	SC/APC
Mounting	Wall
Port, quantity	360

## Material Specifications

Finish	Powder coated
Material Type	Aluminum

## Optical Specifications

Fiber Mode	Singlemode
------------	------------

## Environmental Specifications

Environmental Space	Indoor
---------------------	--------

## Packaging and Weights

Packaging quantity	1
--------------------	---

# FD3-MN360J00MOME0B

---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

