


760258354 | PPL-FA-3U-HCM

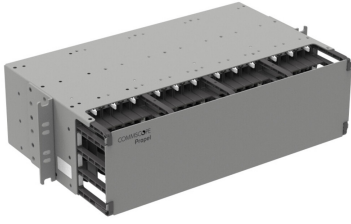

Propel 3RU front access fiber panel for Propel XFrame. Accepts 24, 12 fiber Propel ULL modules, splice cassettes or 6 port adapter packs

- Panel comes with 24 carriers to allow for all front access using standard Propel components. Incoming cable and patch cords are routed at the front of the panel
- HCM (Horizontal Cable Management) panels: HCM panels maximize density within the frame. Patch cords are routed across the front of the panel providing maximum frame density
- For use with 12 fiber Propel components

Product Classification

Portfolio	CommScope®
Product Type	Fiber patch panel
Product Brand	Propel
Product Series	PPL

General Specifications

Color	Gray
Interface, front	Unloaded
Rack Type	EIA 19 in
Rack Units	3
Shelf Movement	Fixed

Dimensions

Height	134 mm 5.276 in
Width	483 mm 19.016 in

Material Specifications

Material Type	Aluminum Steel
----------------------	------------------

Environmental Specifications

Safety Standard	UL
------------------------	----

Packaging and Weights

Packaging quantity 1
Weight, net 3.583 kg | 7.9 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ROHS	Compliant
UK-ROHS	Compliant

