


ARGRPLA7R

Base Product

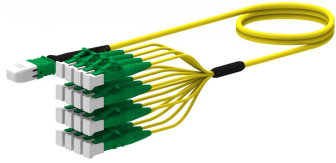

Ultra Low Loss Method A Singlemode MPO16 Non-Pinned to LC/APC, Fiber Cable Assembly, Low Smoke Zero Halogen/Riser

Product Classification

Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber array cable assembly

Product Brand

Propel | SYSTIMAX ULL

Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	1
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	16
Color, boot B	Green
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-16/APC Female
Interface, Connector B	LC/APC
Jacket Color	Yellow
Polarity	Method A
Fibers per Subunit, quantity	16
Total Fibers, quantity	16

Dimensions


Breakout Length 12 in | 24 in | 36 in | 48 in | 60 in | 72 in

ARGRPLA7R

Cable Assembly Length Range (m) 1 – 304

Cable Assembly Length Range (ft) 2 – 999

Ordering Tree

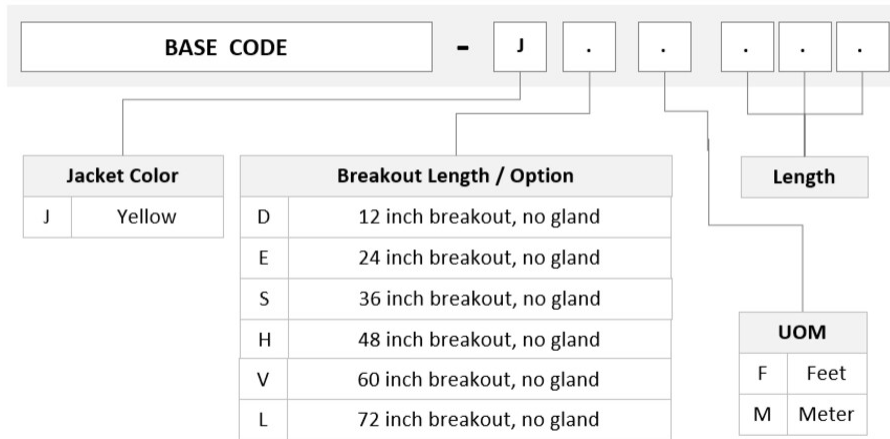

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

ARGRPLA7R



Included Products

- | | | |
|-----------------------------------|---|---|
| 760251072
N-016-MP-8G1-F30YL/D | - | Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser for Light Duty MPO Patchcords, 16 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating |
| 860637445 | - | LC/APC Connector, Singlemode, Green |
| 860661407 | - | MPO16,ULL,FEMALE,SM,GREEN,3mm |